


## Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

## Olympic P/N 3429, MIL-W-16878 Type E PTFE Shielded Cable, 1 Twisted Pair

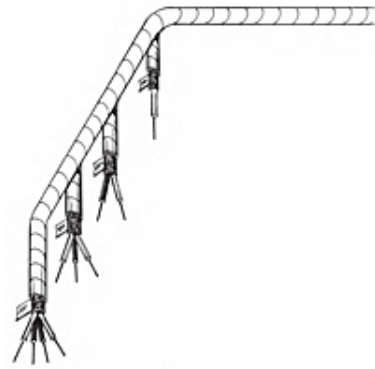

### MIL-W-16878 Type E PTFE Shielded Cable, 1 Twisted Pair

Stranded silver plated Copper conductors, insulated with Type E extruded PTFE, color coded, twisted, braided silver plated Copper shield (90% coverage), white PTFE tape wrapped jacket.

**Temperature Rating:**

-65°C to +200°C

## SPECIFICATIONS

No. of Conductors	2
Conductor Size	16 AWG
Stranding	19/29, Silver Plated Copper
Nom. Wall Thickness	0.011 in
Nom. Jacket Thickness	0.012 in
Nom. O.D.	0.203 in
Voltage	600 V
Insulation	PTFE
Shielding	85% Silver Plated Copper Braid
Jacket	PTFE Wrap, White
Color Code	Black White
Operating Temperature	-65 to 200 °C

RoHS Compliant



RoHS Compliant