


Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

Olympic P/N 3431, MIL-W-16878 Type E PTFE Shielded Cables

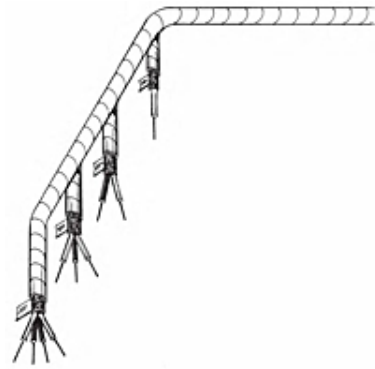

MIL-W-16878 Type E PTFE Shielded Cables

Stranded silver plated Copper conductors, insulated with Type E extruded PTFE, color coded, twisted, braided silver plated Copper shield (90% coverage), white PTFE tape wrapped jacket.

Temperature Rating:

-65°C to +200°C

SPECIFICATIONS

No. of Conductors	4
Conductor Size	16 AWG
Stranding	19/29, Silver Plated Copper
Nom. Wall Thickness	0.011 in
Nom. Jacket Thickness	0.014 in
Nom. O.D.	0.235 in
Voltage	600 V
Insulation	PTFE
Shielding	85% Silver Plated Copper Braid
Jacket	PTFE Wrap, White
Color Code	Black Green Red White
Operating Temperature	-65 to 200 °C

RoHS Compliant



RoHS Compliant