


Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

Olympic P/N 2970, Sound/Broadcast Audio, Foil Shielded Cable

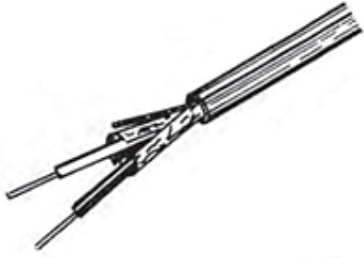

Sound/Broadcast Audio, Foil Shielded Cable

Tinned Copper, PVC insulated, Twisted pair, Aluminum Mylar shield, Stranded tinned Copper drain wire, Chrome PVC jacket.

Temperature Rating

-20°C to 80°C

SPECIFICATIONS

Conductor Size	22 AWG
Stranding	7/30, Tinned Copper
No. of Conductors	2
Insulation	PVC
Nom. Insulation Thickness	0.032 in
Shielding	Aluminum Mylar with Stranded Tinned Copper Drain Wire
Jacket	PVC, Chrome
Nom. Jacket Thickness	0.035 in
Nom. O.D.	0.178 in
UL Style	2464, CM
UL Flame Test	VW-1
Color Code	Black Red
Working Voltage	350 V
UL Voltage	300 V
Operating Temperature	-20 to 80 °C

RoHS Compliant



RoHS Compliant