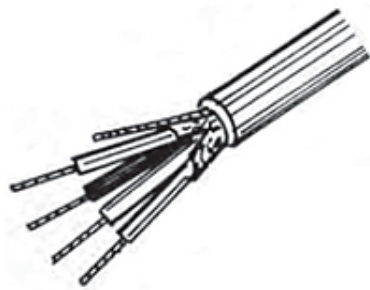


Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

Olympic P/N 2882, Sound/Broadcast Audio, Foil Shielded Cable**Sound/Broadcast Audio, Foil Shielded Cable**

Tinned Copper, Polyethylene insulated, Conductors twisted, Aluminum Mylar shield, 24 AWG stranded tinned Copper drain wire, Chrome PVC jacket.

Temperature Rating

-20°C to 60°C

SPECIFICATIONS

Conductor Size	22 AWG
Stranding	7/30, Tinned Copper
No. of Conductors	4
Insulation	Polyethylene
Nom. Insulation Thickness	0.016 in
Shielding	Aluminum Mylar with Stranded Tinned Copper Drain Wire
Jacket	PVC, Chrome, Sunlight Resistant
Nom. Jacket Thickness	0.025 in
Nom. O.D.	0.215 in
UL Style	2094, CM
UL Flame Test	VW-1
Color Code	Black Clear Green Red
Working Voltage	350 V
UL Voltage	300 V
Operating Temperature	-20 to 60 °C

RoHS Compliant



RoHS Compliant