


Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

Olympic P/N 2886, UV Resistant, Sound/Broadcast Audio, Foil Shielded Cable

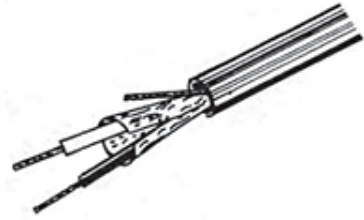

UV Resistant, Sound/Broadcast Audio, Foil Shielded Cable

Tinned Copper, Polyethylene insulated, Twisted pair, Aluminum Mylar shield, 20 AWG stranded tinned Copper drain wire, Chrome PVC jacket.

Temperature Rating

-20°C to 60°C

SPECIFICATIONS

Conductor Size	18 AWG
Stranding	16/30, Tinned Copper
No. of Conductors	2
Insulation	Polyethylene
Nom. Insulation Thickness	0.019 in
Shielding	Aluminum Mylar with Stranded Tinned Copper Drain Wire
Jacket	PVC, Chrome, Sunlight Resistant
Nom. Jacket Thickness	0.028 in
Nom. O.D.	0.222 in
UL Style	2092, CM
UL Flame Test	VW-1, C(UL)
Color Code	Black Clear
Working Voltage	450 V
UL Voltage	300 V
Operating Temperature	-20 to 60 °C

RoHS Compliant



RoHS Compliant