

**Olympic Wire and Cable**

7 Madison Road • Fairfield, NJ 07004


973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

---

**Olympic P/N 2890, Sound/Broadcast Audio, Foil Shielded Cable, CE Compliant**

---

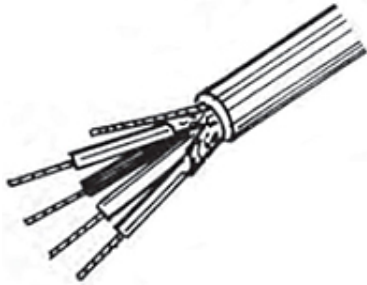

**Sound/Broadcast Audio, Foil Shielded Cable, CE Compliant**

Tinned Copper, PVC insulated, Conductors Twisted, Aluminum Mylar shield overall, 20 AWG stranded tinned Copper drain wire, Chrome PVC jacket.

**Temperature Rating**  
-20°C to 80°C

---

**SPECIFICATIONS**

Conductor Size	18 AWG
Stranding	19/30, Tinned Copper
No. of Conductors	4
Insulation	SR-PVC
Nom. Insulation Thickness	0.010 in
Shielding	Aluminum Mylar with Stranded Tinned Copper Drain Wire
Jacket	PVC, Chrome
Nom. Jacket Thickness	0.035 in
Nom. O.D.	0.245 in
UL Style	2464, CM CMG
UL Flame Test	VW-1
Color Code	Black Green Red White
Working Voltage	300 V
UL Voltage	300 V
Operating Temperature	-20 to 105 °C

RoHS Compliant



RoHS Compliant