


## Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

# Olympic P/N 2890, Sound/Broadcast Audio, Foil Shielded Cable, CE Compliant

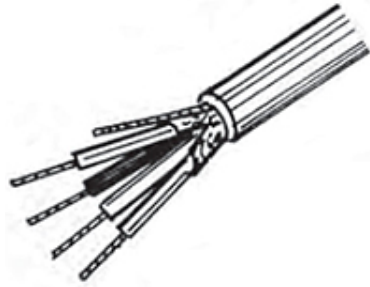

## Sound/Broadcast Audio, Foil Shielded Cable, CE Compliant

Tinned Copper, PVC insulated, Conductors Twisted, Aluminum Mylar shield overall, 20 AWG stranded tinned Copper drain wire, Chrome PVC jacket.

### Temperature Rating

-20°C to 80°C

## SPECIFICATIONS

|                           |   |
|---------------------------|---|
| Conductor Size            | 18 AWG  |
| Stranding                 | 19/30, Tinned Copper                                  |
| No. of Conductors         | 4   |
| Insulation                | SR-PVC  |
| Nom. Insulation Thickness | 0.010 in  |
| Shielding                 | Aluminum Mylar with Stranded Tinned Copper Drain Wire |
| Jacket                    | PVC, Chrome   |
| Nom. Jacket Thickness     | 0.035 in  |
| Nom. O.D.                 | 0.245 in  |
| UL Style                  | 2464, CM CMG  |
| UL Flame Test             | VW-1  |
| Color Code                | Black<br>Green<br>Red<br>White                        |
| Working Voltage           | 300 V   |
| UL Voltage                | 300 V   |
| Operating Temperature     | -20 to 105 °C   |

RoHS Compliant



RoHS Compliant