


Olympic Wire and Cable

7 Madison Road • Fairfield, NJ 07004

973.227.7996 800.526.2269 • Fax: 973.227.1606

email: sales@olympicwire.com

Olympic P/N 2892/4, Sound/Broadcast Audio, Foil Shielded Cable

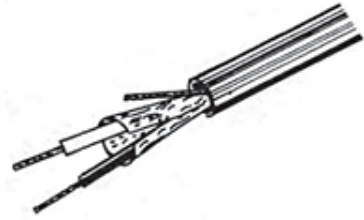

Sound/Broadcast Audio, Foil Shielded Cable

Tinned Copper, Polyethylene insulated, Conductors twisted, Aluminum Mylar shield, 18 AWG stranded tinned Copper drain wire, Chrome PVC jacket.

Temperature Rating

-20°C to 60°C

SPECIFICATIONS

Conductor Size	16 AWG
Stranding	19/29, Tinned Copper
No. of Conductors	4
Insulation	Polyethylene
Nom. Insulation Thickness	0.032 in
Shielding	Aluminum Mylar with Stranded Tinned Copper Drain Wire
Jacket	PVC, Chrome
Nom. Jacket Thickness	0.031 in
Nom. O.D.	0.385 in
UL Style	20253, CM
UL Flame Test	VW-1
Color Code	Black Clear Green Red
Working Voltage	600 V
Operating Temperature	-20 to 60 °C

RoHS Compliant



RoHS Compliant