


Model BNC-C  
BNC Male To Male Cable Assembly

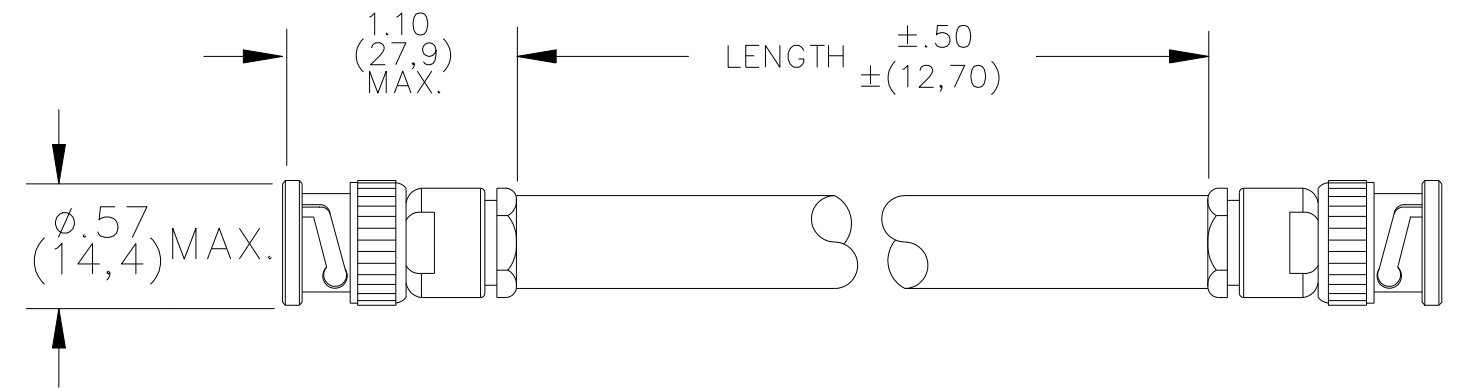

| Part No. | Cable Type | Capacitance<br>PF/ft. | Nominal<br>Impedance | Cable Color | Cable O. D. |
|----------|------------|-----------------------|----------------------|-------------|-------------|
| BNC-C-XX | RG58C/U    | 30.8                  | 50 Ohms              | Black       | 0.195"      |
|          |            |                       |                      |             |             |

**MATERIALS:**  
BNC Body: Brass, Tarnish Resistant Plating, Center Contact: Gold Plated Brass  
Dielectric: PTFE

**RATINGS:**  
Operating Voltage: Shield-Earth: 30VAC/60VDC Max.  
Inner Conductor/Shield: 500VRMS Max.  
Operating Temperature: +80°C (+176°F) Max.  
Nominal Impedance: 50 Ohms

**ORDERING INFORMATION:** Model BNC-C-XX  
XX = Cable Length in inches, length tolerance:  $\pm 0.5''$   
Standard Lengths: 18'', 24'', 36'', 48'', 60'', 72'', 96'', & 600''.