

Features:

- ✓ Can be vertically stacked on top of each other
- ✓ Fits standard banana safety-style jacks
- ✓ Fits DMM with safety-style banana jacks
- ✓ Simple assembly
- ✓ Complies to International Safety Standard IEC 1010-2-031
- ✓ Accepts 18 AWG test lead wire (e.g. Pomona model: 6733 or 6734)

Materials:

| | |
|--------------|--------------------------------|
| Banana Jack: | Nickel Plated Brass |
| Banana Plug: | Nickel Plated Beryllium Copper |
| Insulation: | Lucel |

Ratings:

| | |
|--------------------|--|
| Voltage / Current: | * 1000 Vrms, CAT III, 20 A, IEC 1010-2-031 |
| Temperature: | -10 to +55 C |








Ordering Information:

| | |
|--------|---|
| 6721-0 | Black, Do-It-Yourself Stacking Sheath Banana Plug |
| 6721-2 | Red, Do-It-Yourself Stacking Sheath Banana Plug |

* *When plug is correctly assembled and terminated.*

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).
All specifications are to the latest revisions. Specifications are subject to change without notice.
Registered trademarks are the property of their respective companies. Made in USA

Sales: 800-490-2361 Fax: 888-403-3360 Technical Assistance: 800-241-2060
For "Where to Buy" information, visit the Pomona web site at www.pomonaelectronics.com

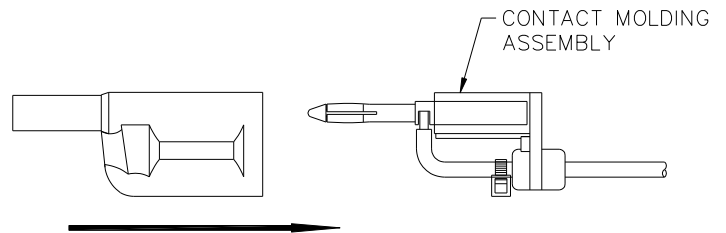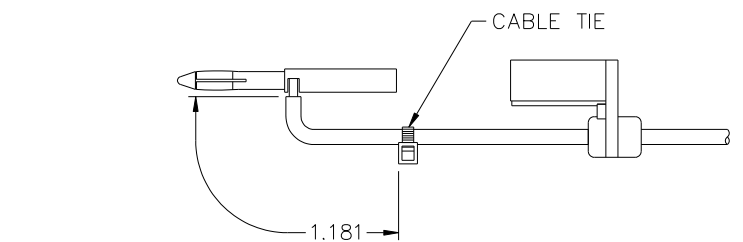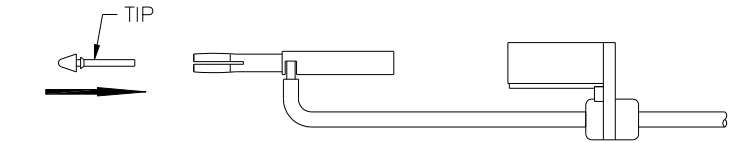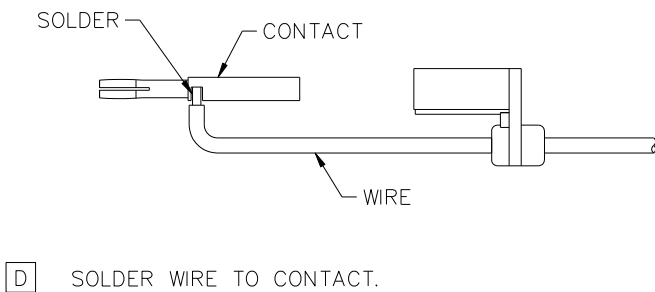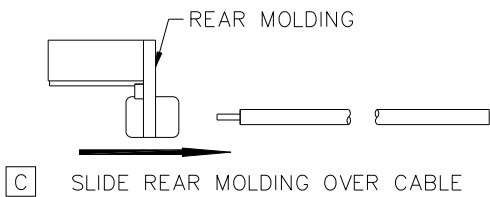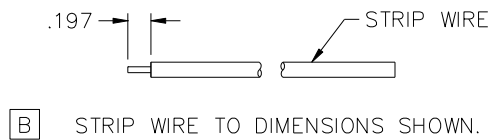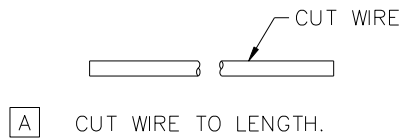

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).
All specifications are to the latest revisions. Specifications are subject to change without notice.
Registered trademarks are the property of their respective companies. Made in USA

Sales: 800-490-2361 Fax: 888-403-3360 Technical Assistance: 800-241-2060
For "Where to Buy" information, visit the Pomona web site at www.pomonaelectronics.com