



Models 6873, 6874
1/4" Phone Plug 2 Pole (Mono), 3 Pole (Stereo)



Model 6873 1/4" Phone Plug 2 Pole (Mono)



Model 6874 1/4" Phone Plug 3 Pole (Stereo)

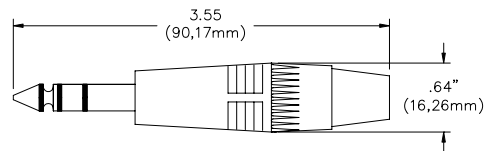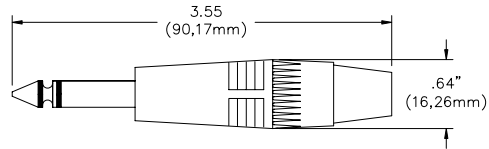

Use Pomona 1/4" phone plugs for your audio applications.

Features

- Mono and stereo versions.
- Gold plating for low contact resistance.
- Solderable.

Materials

- Body is made of die cast zinc alloy with tarnish resistant black-nickel plating.
- Strain relief clamp designed for durability: POM.
- Contacts are nickel-plated brass with gold plated tips.

Ordering Information

Model: 6873, 6874

Specifications

Number of Contacts	6873: 2 pole (mono) 6874: 3 pole-tip, ring, sleeve (stereo)
Termination	Solder
AWG	2 pole (mono)-16 AWG / 1.5mm ² 3 pole (stereo)-18 AWG / 1.0mm ²
Pull Strength	45 lbs. (typical)
Cable O.D. Range	3.0 mm – 6.0 mm (0.118"-0.236")

USA: Sales: 800-490-2361 Technical Support: 800-241-2060 Fax: 888-403-3360

Europe: 31-(0) 40 2675 150 **International:** 425-446-5500

e-mail: technicalsupport@pomonatest.com

Where to Buy: www.pomonaelectronics.com

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm). All specifications are to the latest revisions. Specifications are subject to change without notice. Registered trademarks are the property of their respective companies.