


## Model 3786 Minigrabber® Test Clips To Double Banana Plug

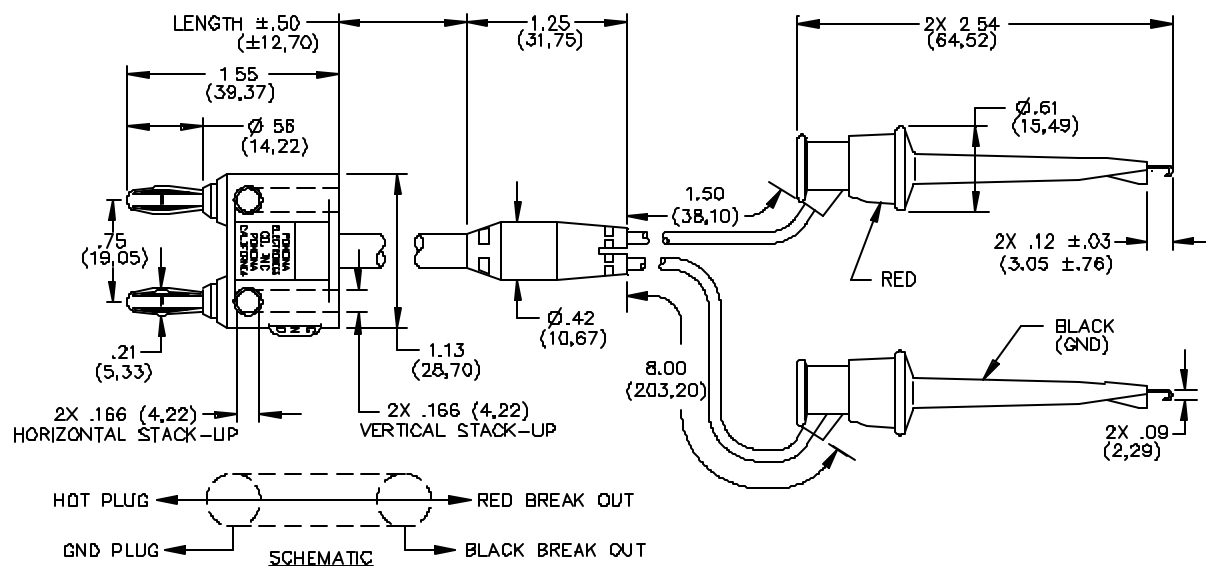

### FEATURES:

- Converts double Banana Jacks to Minigrabber Test Clip.
- Lengths other than those specified are available upon request.

### MATERIALS:

Conn: 1<sup>st</sup> End-Double Banana Plug

Material: Spring-Beryllium Copper per QQ-C-533, Alloy 172, Cond. HT.

Plug Body: Brass per QQ-B-626, Alloy 360, ½ Hard.

Finish: Nickel plated per QQ-N-290, Class 2, 200/300 microinches.

Insulation: Polypropylene molded to plug bodies and cable. Color matches color of cable.

Marking: "POMONA ELECTRONICS CO., INC. POMONA CALIFORNIA".

Cable: RG58C/U.

Marking: "POMONA 3786-C-XX".

Molded Breakout: PVC molded to breakout leads and cable. Color: Black Breakout Leads: 20 AWG, length.

41 x 36 T.C., PVC insulated, 2.21 (.087) O.D.

One Red Lead, one Black Lead

Conn: 2<sup>nd</sup> End-Minigrabber®

Material: Contact – Beryllium Copper per QQ-C-533, Alloy 165, ¼ HM.

Spring: stainless steel, Alloy 302.

Finish: Contact – Gold plated per MIL-G-45204, Type I, Class 00.

Insulation: Glass filled Nylon. Color: One Red and one Black.

Marking: "POMONA ELECTRONICS  
"MINIGRABBER®".

### RATINGS:

Operating Voltage: 300 VRMS/DC

Operating Temperature: +50°C. (+122°F.) Max

Current: 5 Amperes

**ORDERING INFORMATION:** Model 3786-C-XX

XX=Cable Length, Standard Length: 18" (457), 24"

(610), 36" (914), 48" (1219), 60" (1524)

Ordering Example: Model 3786-C-60 indicates 60" in

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA