

RECOMMENDED  
 PC MOUNTING

**MATERIALS:**

Body: Tarnish Resistant Nickel Plated Brass  
 Body Mounting Pins: Nickel Plated Brass  
 Center Contact: Gold Plated Beryllium Copper  
 Center Mounting Pin: Gold Plated Brass  
 Dielectric: Teflon per L-P-403

**RATINGS:**


Operating Voltage: Hands free usage in controlled voltage environments:  
 500 Vrms maximum. *For CE compliance:* not intended for hand-held use at voltages above 33 Vrms/70 Vdc.

Operating Temperature: -85°F to +329° F (-65°C to +165°C).

Nominal Impedance: 50 Ohms

**ORDERING INFORMATION:** Model 4788

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ± .005" (.127 mm).  
 All specifications are to the latest revisions. Specifications are subject to change without notice.  
 Registered trademarks are the property of their respective companies.

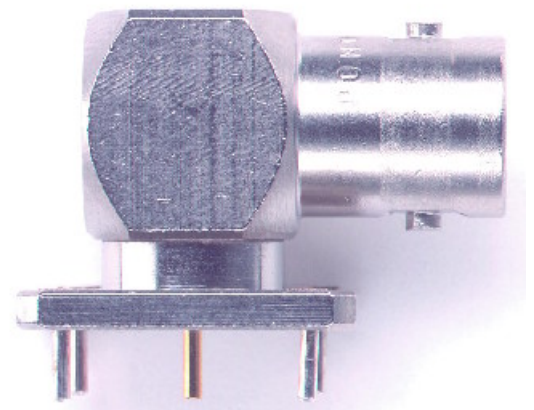

Sales: 800-490-2361 Fax: 888-403-3360 Technical Support: 800-241-2060 (technicalsupport@pomonatest.com)  
 For "Where to Buy" information, visit the Pomona web site at [www.pomonaelectronics.com](http://www.pomonaelectronics.com)