


## Model 5268 BNC (Male) To Single Stackable Banana Plugs

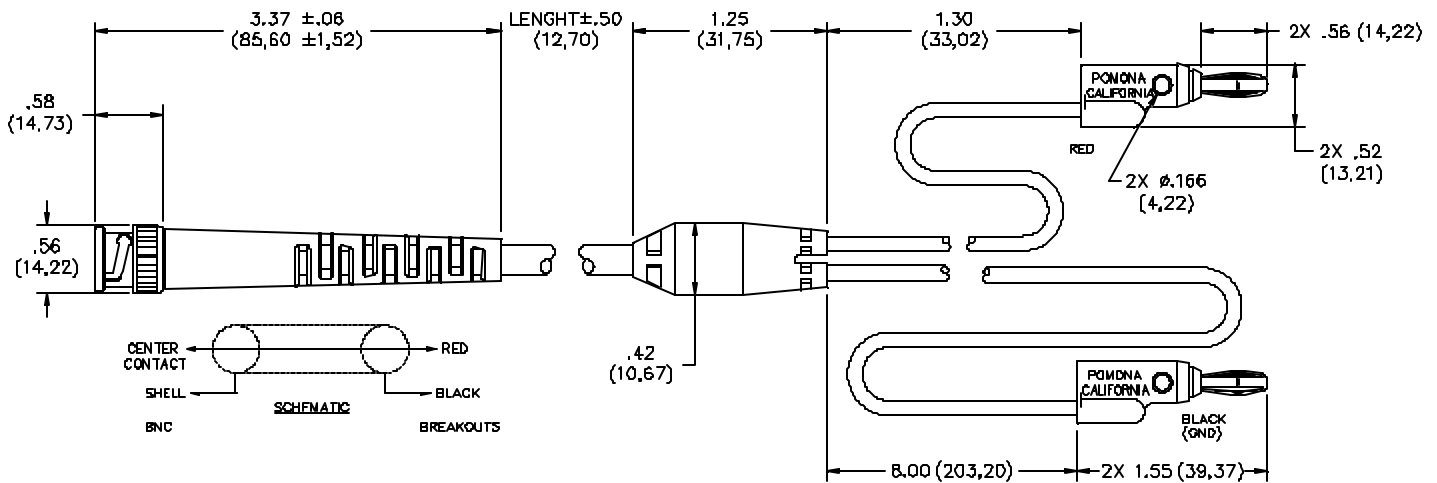

### FEATURES:

- Cable enables BNC based test instruments to interface to banana jacks.
- Banana plugs can be stacked on top or side of the banana plugs for additional test versatility.
- BNC connector, wire breakout and banana plugs are molded directly to the cable for added pull strength.

### MATERIALS:

BNC: Body: Brass, Nickel Plated, Center Pin: Brass, Gold Plated, Impedance: 50 Ohms

Strain Relief: PVC, Color: Black

Cable: RG58C/U, Impedance: 50 Ohms Nom., Cap. (pF/Ft). 30.8, O.D. .195" (5,0 mm) Nom., Color: Black

Marking: "POMONA 5268-C-XX"

Molded Breakout: PVC, Color: Black

Breakout Leads: 20 AWG, Stranding 41 x 36 t.c., PVC Insulated, .087" (2,21mm) O.D.

Banana Plugs: Body – Brass, Nickel Plated

Spring – Beryllium Copper, Nickel Plated

Insulation – Polypropylene, Color: One Black, One Red

### RATING:

Operating Temperature: 50°C (+122°F) Max.

Voltage: Hand-held testing: 30VAC/60VDC Max.

Hands free testing in controlled voltage environments: 500 WVDC Max.

### ORDERING INFORMATION: Model 5268-C-XX

XX = Cable Length Std. Lengths: 12" (30,5 cm), 24" (60,96 cm), 36" (91,44 cm), 48" (121,92 cm) & 60" (152,40 cm). Additional lengths can be quoted upon request.

Ordering Example: 5268-C-36 , Cable length will be 36" (91,44 cm) long.

All dimensions are in inches. Tolerances (except noted): .xx = ±.02" (.51 mm), .xxx = ±.005" (.127 mm).

All specifications are to the latest revisions. Specifications are subject to change without notice.

Registered trademarks are the property of their respective companies. Made in USA