

# My Account


- [Manage My Part Lists](#)
- [Manage My Downloads](#)
- [Sign In](#)
- [Register](#)

# Customer Support

- [Support](#)
- [RoHS Support Center](#)
- [Glossary of Terms](#)
- [Subscribe to Newsletter](#)

[Home](#) > [Products](#) > [By Type](#) > [Relays](#) > [Product Feature Selector](#) > Product Details

# KHU-17D16-24 Product Details

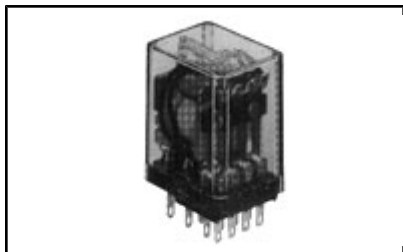

**KHU-17D16-24**

TE Part Number: 5-1393123-2



Active



[Add to Part List](#)

## Industrial Relays (General Purpose)



[Always EU RoHS compliant but not ELV Compliant \(Statement of Compliance\)](#)

### Product Highlights:

- KHU Series
- Contact Arrangement = 4 Form C, 4PDT, 4 C/O
- Contact Current Rating = 1 Amps.
- Monostable Coil Magnetic System
- Without Coil Suppression Diode

[View all Features](#) | [Find Similar Products](#)

## Quick Links

- [Check Pricing & Availability](#)
- [Search for Tooling](#)
- [Product Feature Selector](#)
- [Contact Us About This Product](#)

## Documentation & Additional Information

### Product Drawings:

- None Available

### Catalog Pages/Data Sheets:

- [KHA General Purpose Dry Circuit to 5A Multicontact A...](#) (PDF, English)

### Product Specifications:

- None Available

### Application Specifications:

- None Available

### Instruction Sheets:

- None Available

### CAD Files:

- None Available

### Additional Information:

- [Product Line Information](#)

### Additional Product Images:

- [Schematic](#)
- [PCB Layout](#)
- [Wiring Diagram](#)

### Related Products:

- [Tooling](#)

[List all Documents](#)

## Product Features (Please use the Product Drawing for all design activity)

### Product Type Features:

- [Termination Type](#) = Solder Terminals

### Electrical Characteristics:

- [Contact Current Rating \(Amps.\)](#) = 1
- [Coil Resistance \(•\)](#) = 650
- [Actuating System](#) = DC
- [Coil Power, Nominal \(W\)](#) = 0.90
- [Input Voltage \(VDC\)](#) = 24

### Body Related Features:

- Series = KHU
- Polarized = No

### Contact Related Features:

- [Mounting Options](#) = PC Board, Socket
- [Enclosure](#) = Dust Cover
- FCC Part 68 Isolation = No
- Relay Type = General
- [Contact Material](#) = Bifurcated Cross Bar, Gold Overlay Silver
- Approx. Dimensions (L x W x H) (mm [in]) = 28.20 x 21.80 x 34.90 [1.111 x .858 x 1.375]
- Wiring Diagram = 4 Form C
- Approved Standards = UL Recognized, CSA Certified

### Configuration Related Features:

- [Contact Arrangement](#) = 4 Form C, 4PDT, 4 C/O
- [Coil Magnetic System](#) = Monostable
- [Coil Suppression Diode](#) = Without
- [Coil Selection Criteria](#) = Nominal Voltage
- Coil Latching = Without
- [LED Indicator](#) = Without

### Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS/Not ELV Compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- RoHS/ELV Compliance History = Always was RoHS not ELV compliant

### Other:

- Brand = Potter & Brumfield