




What can we help you find?

[Products](#) [Industries](#) [Resources](#) [About TE](#) [My Account](#) [Innovation](#) [Support Center](#)

P40P42A12P1-120 Product Details

[Share](#) [Print](#) [Email](#)

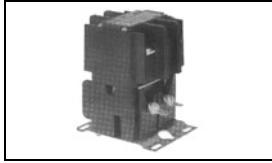

P40P42A12P1-120

TE Internal Number: 7-1393132-0

Active

Contactors

Converted to EU RoHS but not ELV Compliant
(Statement of Compliance)

Product Highlights:

- Contactor Type = Definite Purpose
- P40 Series
- AC Actuating System
- 3 Poles
- Contact - Arrangement = 3 Form X, 3PST-NO-DM

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Documentation & Additional Information	
<p>Product Drawings:</p> <ul style="list-style-type: none"> • None Available <p>Catalog Pages/Data Sheets:</p> <ul style="list-style-type: none"> • P30/P40 Definite Purpose Magnetic Contactor 30/40 Am... (PDF, English) <p>Product Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Application Specifications:</p> <ul style="list-style-type: none"> • None Available <p>Instruction Sheets:</p> <ul style="list-style-type: none"> • None Available <p>CAD Files:</p> <ul style="list-style-type: none"> • None Available 	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling

[List all Documents](#)

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Contactor Type = Definite Purpose • Series = P40 • Terminal Configuration = 10-32 Screw • Wire Size (mm² [AWG]) = 8 <p>Mechanical Attachment:</p> <ul style="list-style-type: none"> • Mounting Plate = With <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Actuating System = AC • Contact Rating = 40A • Coil Voltage, Max. (VAC) = 120 <p>Termination Features:</p> <ul style="list-style-type: none"> • Coil Termination = 8-32 Screw, Quick Connect 	<p>Contact Features:</p> <ul style="list-style-type: none"> • Number of Poles = 3 • Contact Base Material = Silver Cadmium Oxide <p>Configuration Features:</p> <ul style="list-style-type: none"> • Contact - Arrangement = 3 Form X, 3PST-NO-DM • Auxiliary Switch Contact Arrangement = None <p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS/Not ELV Compliant • Lead Free Solder Processes = Not relevant for lead free process • RoHS/ELV Compliance History = Converted to comply with RoHS not ELV directives <p>Packaging Features:</p> <ul style="list-style-type: none"> • Packaging Method = Individual <p>Other:</p> <ul style="list-style-type: none"> • Brand = Potter & Brumfield

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)