


**Option Choices**

Selection Option	Your Choice
Knob Shape	4-Prong Knob
Material	Thermoset
Insert	Brass Insert
Insert or Stud Measurement	English



**Dimension Chart**

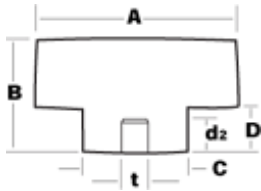

**Part Dimensions**

Part Number	A	B	C	D	t	d2
044P12BI2520	1.250	0.700	0.550	0.300	1/4-20	0.375

**Quantity/Price Break**

Part: 044P12BI2520	
Quantity	
100-499	
500-999	
1000-2499	
2500-4999	
Please <a href="#">contact us</a> for pricing on orders over 5000 knobs	

[Start New Selection](#)

[Instrument](#) | [Consumer](#) | [Transilluminated & Military](#) | [Clamp & Ball Knobs](#) | [Catalog](#)

[Distributors](#) | [About Us](#) | [What's New](#) | [Contact Us](#) | [Government NSN Stock](#) | [Home](#)



**ELECTRONIC HARDWARE CORPORATION** 320 Broad Hollow Road, Farmingdale, NY 11735  
PHONE 631.752.1950 FAX 631.752.1971 EMAIL [sales@ehcknobs.com](mailto:sales@ehcknobs.com) **1-800-752-1680**