

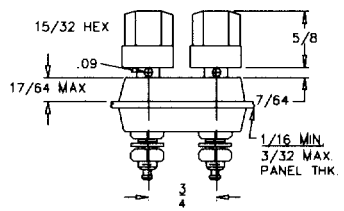
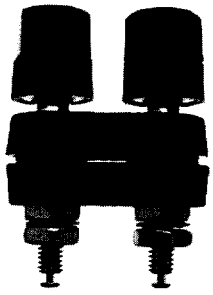


DUAL BINDING POSTS



BINDING POSTS

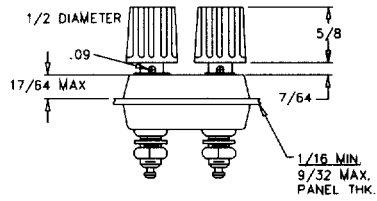



A

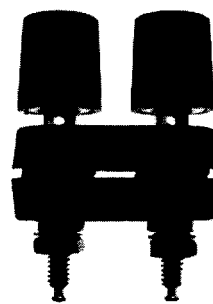

B

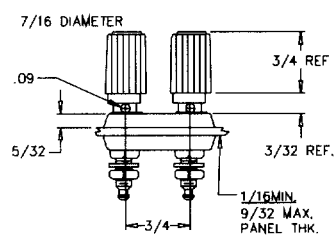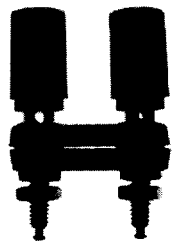

C

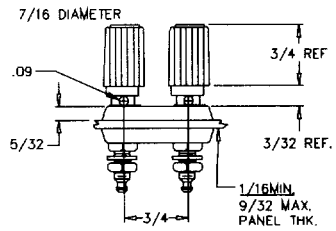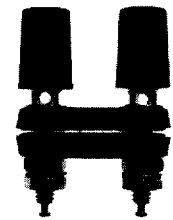

D

- ◆ Fluted or hex insulated post heads are molded Lexan Polycarbonate. Captivated to prevent loss.
- ◆ Body is brass with tin plating.
- ◆ Insulated washers are molded polycarbonate and completely insulate post from panel. Keyed to panel and body to prevent rotation.
- ◆ Body mounts into dual holes with 3/4" centers.
- ◆ Connects with .080" phone tip plug, spade lug (1/4"), standard banana plug, alligator clip, wire (to #14) and shorting links.
- ◆ To connect circuit, wrap wire around solder turret or attach to solder lug between nuts. (Lug not supplied.)
- ◆ Please refer to Table A (page 26) for ratings.
- ◆ All posts shown here are available with alternating head colors in red or black as indicated in table.

PART NO.	FIG.	MOUNTING HOLE	POST THREAD	HEAD SHAPE	HEAD COLORS
269BB	A	1/2	10-32	Hex	Black - Black
269RB					Red - Black
269RR					Red - Red
1808BB			8-32		Black - Black
1808RB					Red - Black
1808RR					Red - Red
1813BB	B	1/2	10-32	Hex	Black - Black
1813RB					Red - Black
1813RR					Red - Red
1812BB			8-32		Black - Black
1812RB					Red - Black
1812RR					Red - Red
1477BB	C	3/8	6-32	Fluted	Black - Black
1477RB					Red - Black
1477RR					Red - Red
1810BB			8-32		Black - Black
1810RB					Red - Black
1810RR					Red - Red
1814BB	D	3/8	6-32	Fluted	Black - Black
1814RB					Red - Black
1814RR					Red - Red
1809BB			8-32		Black - Black
1809RB					Red - Black
1809RR					Red - Red

