


VECTORBORD®PLUGBORD™ PART NO. : 3797-2

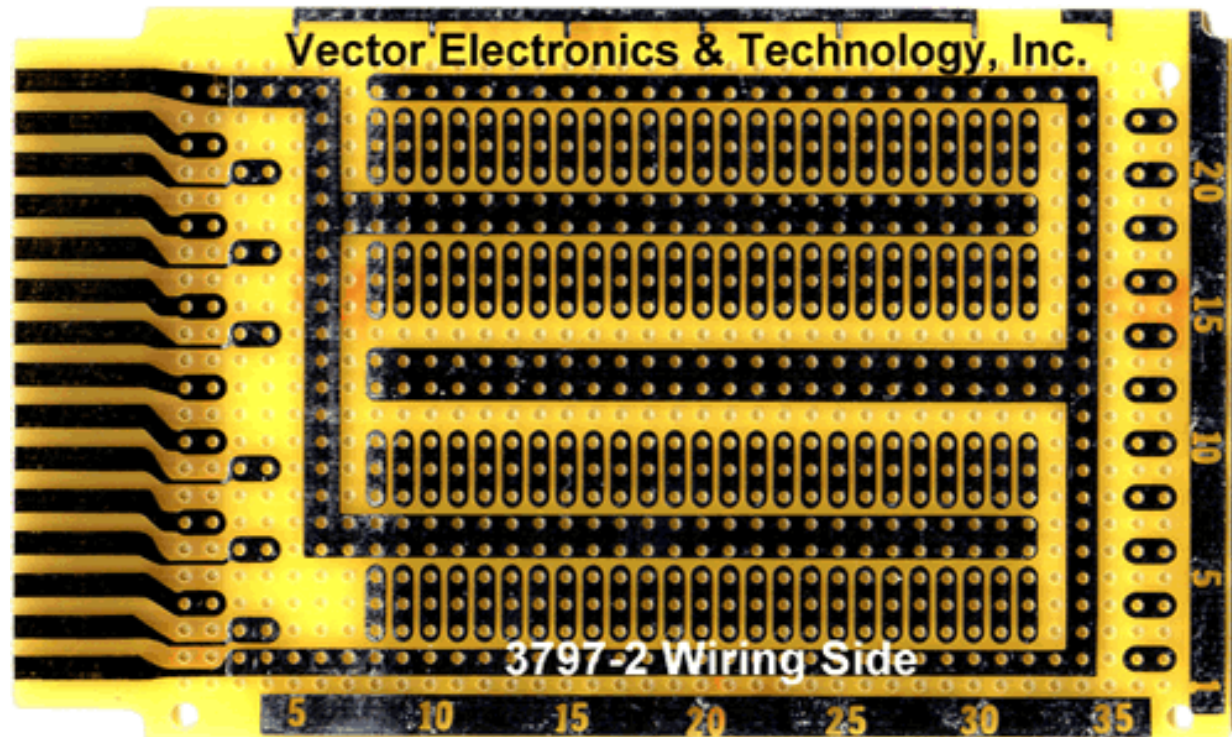

Description :

- 2.73" X 4.5" X 0.062, Hole Dia.: 0.042", Grid: 0.100" X 0.100"
- 3-Hole Solder Pads Only
- 3-hole solder pads (0.28" x 0.080") for interconnecting multi-ple component leads
- All pad and bus surfaces solder coated for user convenience
- No etch or plating on reverse side
- Convenient easy-to-read hole marking legend on wiring side
- Layout paper and instructions included [Layout Paper\(PDF\)](#)

Circuit Pattern :	3-Hole Solder Pad
Contacts :	15/30 @ 0.156" Centers Ni / Gold
16 Pin DIP Capacity :	4
Hole Diameter :	0.042" { 1.0668 mm }
Grid :	0.100" X 0.100" { 2.54mm X 2.54mm }
Dimension { H, W, T } :	2.73" X 4.5" X 0.062"
Material :	CEM-1
Wire-Wrap Terminals :	T44, T46, T49 & T68
Solder Connector :	R630
Wire-Wrap Socket Pins :	R32
Extender :	3690-10
Recommended Card Cage:	CCK 12 Series Card Cages
NEMA Grade :	CEM-1
UL Flammability Class :	94V - 0