


VECTORBORD® CIRCBOARD™ PART NO. : 8015-1

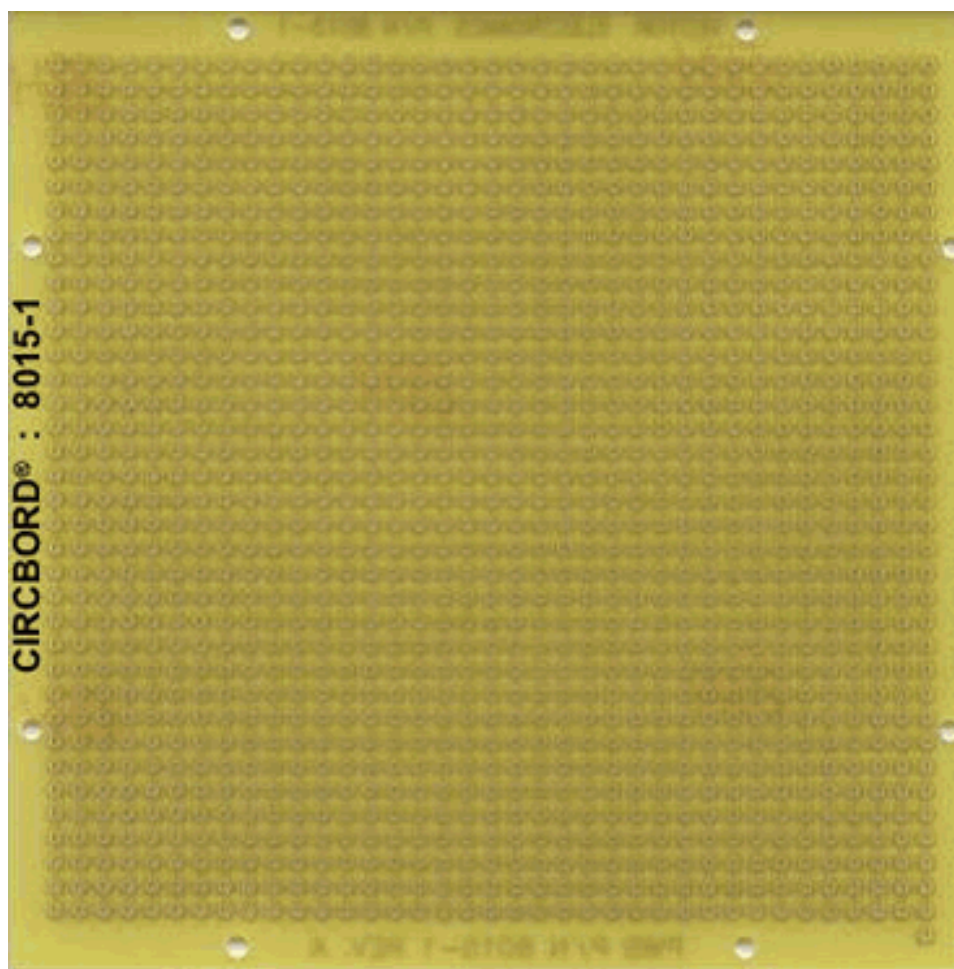

Description :

4.0" x 4.0", Hole Dia.: 0.042", Grid: 0.100" x 0.100"

Pad-Per-Hole, One Side Pattern

Isolated round pads around each holes

0.080" diameter, isolated solder pad around each hole on both sides

Unrestricted component placement and extended area for high density applications

Circuit Pattern :	Pad-Per-Hole (One Side Pattern Plated Holes)
Contacts :	N/A
16 Pin DIP Capacity :	72
Hole Diameter :	0.042" { 1.0668 mm }
Grid :	0.100" x 0.100" { 2.54mm X 2.54mm }
Dimension { H, W, T } :	4.0" x 4.0" x 0.062"
Material :	FR4 Epoxy Glass { MIL - P13949 type Gf }
Wire-Wrap Terminals :	T44, T46, T49, T68
Solder Terminals :	T42-1, K24C
Wire-Wrap Socket Pins :	R32
NEMA Grade :	FR4
UL Flammability Class :	94V - 0