


VECTORBORD® CIRCBORD™.... PART NO. : 8016-1

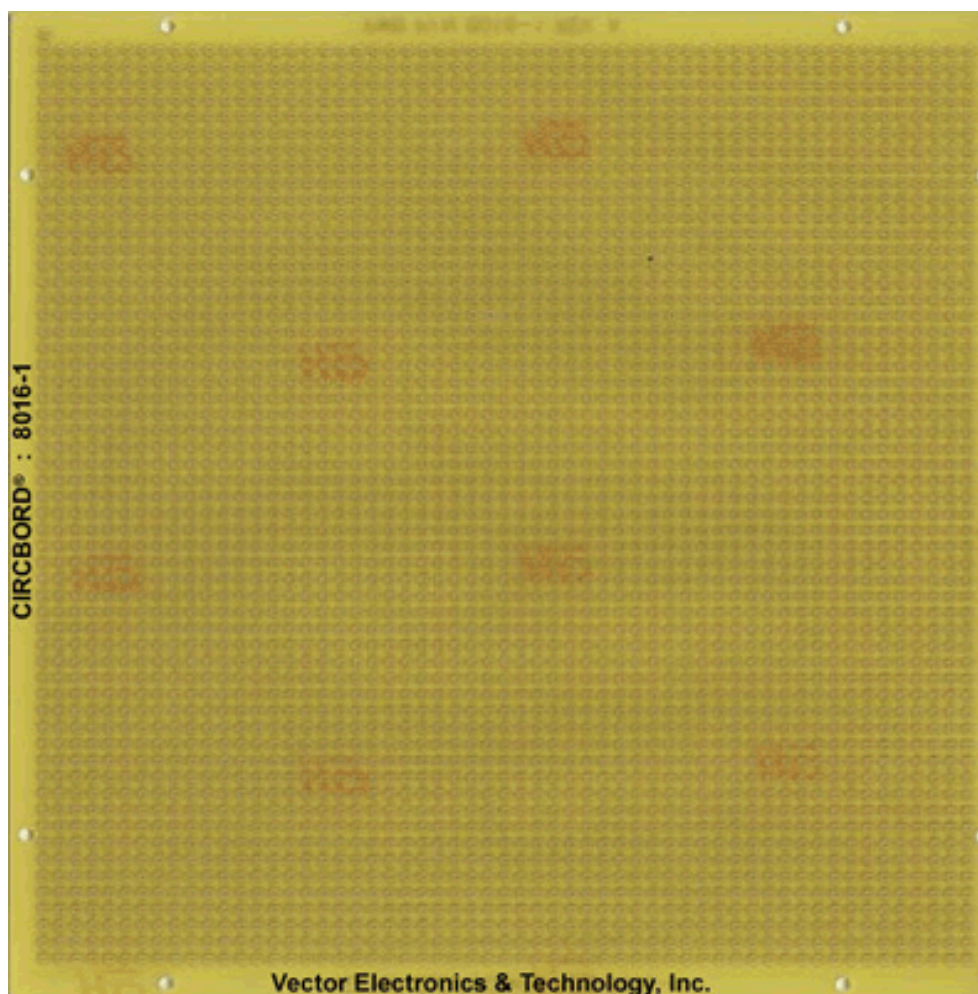

Description :

6.0" x 6.0", Hole Dia.: 0.042", Grid: 0.100" x 0.100"

Pad-Per-Hole., One Side Pattern

Isolated solder pad around each hole on one side.

Unrestricted component placement and extended area for high density applications

Circuit Pattern :	Pad-Per-Hole
Contacts :	N/A
16 Pin DIP Capacity :	165
Hole Diameter :	0.042" { 1.0668 mm }
Grid :	0.100" x 0.100" { 2.54mm X 2.54mm }
Dimension { H, W, T } :	6.0" x 6.0" x 0.062"
Material :	FR4 Epoxy Glass { MIL - P13949 type Gf }
Wire-Wrap Terminals :	T44, T46, T49, T68
Solder Terminals :	T42-1, K24C
Wire-Wrap Socket Pins :	R32
NEMA Grade :	FR4
UL Flammability Class :	94V - 0