


**VECTORBORD® CIRCBORD™ .... PART NO. : 106P106-1**

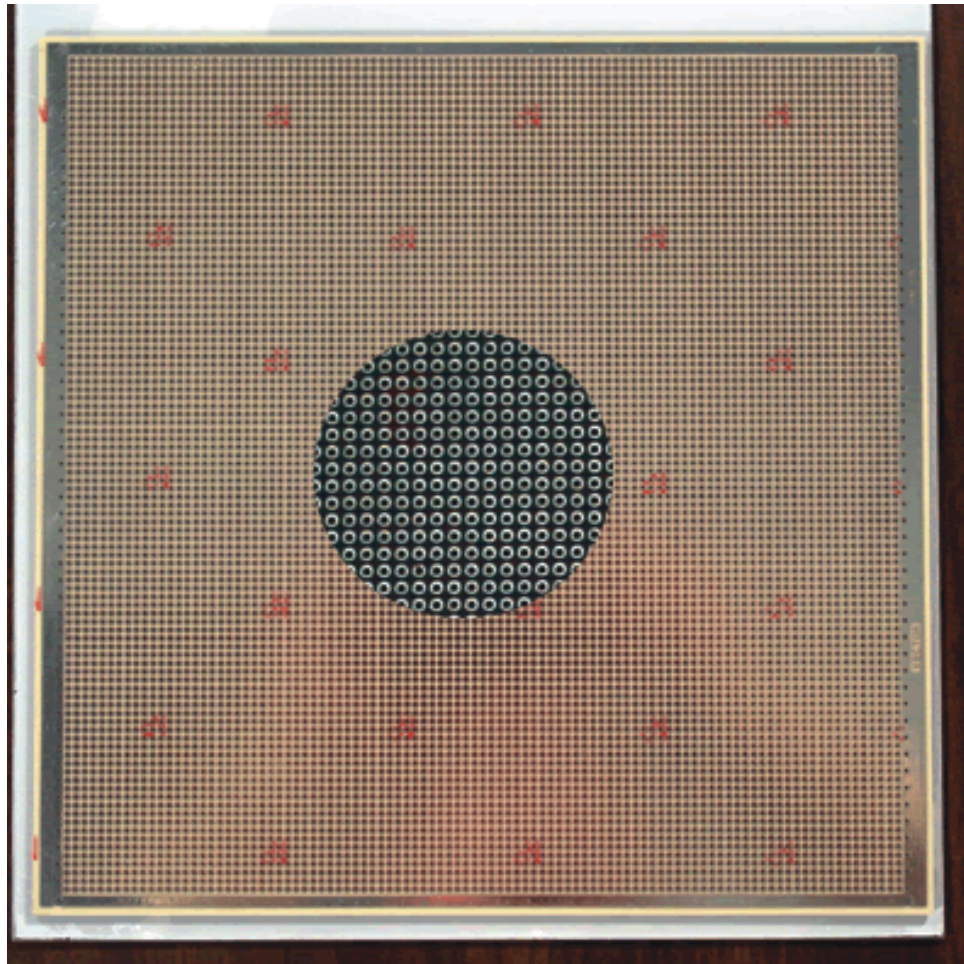

**Description :**

**10.6" x10.6", Hole Dia.: 0.042", Grid: 0.100" x 0.100"**

**Pad-Per-Hole & Peripheral Ground Plane 2 Sides**

**0.080" diameter, isolated pads around each hole, not plated through and ground plane.**

<b>Circuit Pattern :</b>	<b>Pad-Per-Hole &amp; Peripheral Ground Plane 2 Sides</b>
<b>Contacts :</b>	<b>N/A</b>
<b>16 Pin DIP Capacity :</b>	<b>275</b>
<b>Hole Diameter :</b>	<b>0.042" { 1.0668 mm }</b>
<b>Grid :</b>	<b>0.100" x 0.100" { 2.54mm X 2.54mm }</b>
<b>Dimension { H, W, T } :</b>	<b>10.6" x 10.6" x 0.062"</b>
<b>Material :</b>	<b>FR4 Epoxy Glass { MIL - P13949 type Gf }</b>
<b>Wire-Wrap Terminals :</b>	<b>T44, T46, T49, T68</b>
<b>Solder Terminals :</b>	<b>T42-1</b>
<b>Wire-Wrap Socket Pins :</b>	<b>R32</b>
<b>NEMA Grade :</b>	<b>FR4</b>
<b>UL Flammability Class :</b>	<b>94V - 0</b>