


## Marksman® Iron (40 Watt)

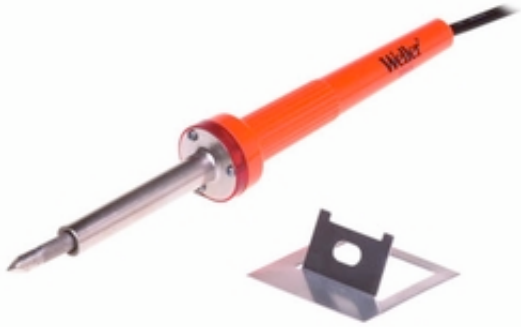

Product Details	
Catalog No.	SP40L
UPC Code	037103169181
Type	Non-temperature Controlled
Wattage	40 W
Temperature Range	900° F
Cord Length	6 ft.
Components Supplied	MT10
Packaging	Peg Hook/Retail Packaging
Tech. Spec.	<a href="#">Solder Safety Warnings.pdf</a>
Lineart	<a href="#">SP40L.pdf</a>
Low Res. Image	<a href="#">SP40L_100.jpg</a>
High Res. Image	<a href="#">SP40L_300.jpg</a>
Stock Item	Normal Stock Item

### Product Features:

- New indicator light allows you to instantly see that the iron is on
- Fine quality consumer mini iron, 8-1/4"/210mm long
- Lightweight pencil iron, ideal for hobbies
- MT10 1/4"/10mm diameter replaceable nickel-plated copper tip
- Develops 900°F/482°C temperature
- Stainless steel barrel and heat and impact resistant handle
- **IMPORTANT:** Use only Weller® tips
- UL listed - cUL version available