



## V-Notch Stripper

Catalog # 45-101



---

### Features

- Cuts copper or aluminum wire, solid or stranded
- Rotating cam wheel adjusts to strip 10-24 AWG wire
- Looping holes for solid wire
- Locking hasp

## Super T®-Stripper Wire Strippers—Static Dissipative

- Static dissipative grips for dispersing static charge buildup through the operator to the ground (operator must be grounded via wrist strap or other grounding device)




- Locking pawl to keep stripper in closed position

Description	Solid	Stranded	Cat. No.
Super T®-6 T®-Stripper Wire Stripper w/static dissipative grips	14-24	16-26	<b>45-316</b>
Super T®-7 T®-Stripper Wire Stripper w/static dissipative grips	22-30	24-32	<b>45-317</b>


## V-Notch Stripper

- Cuts copper or aluminum wire, solid or stranded
- Rotating cam wheel adjusts to strip 10-24 AWG wire
- Looping holes for solid wire
- Locking hasp

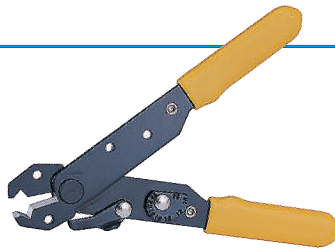

Description	Cat. No.
V-Notch Stripper	<b>45-101</b>

## 7-in-1 Stripper

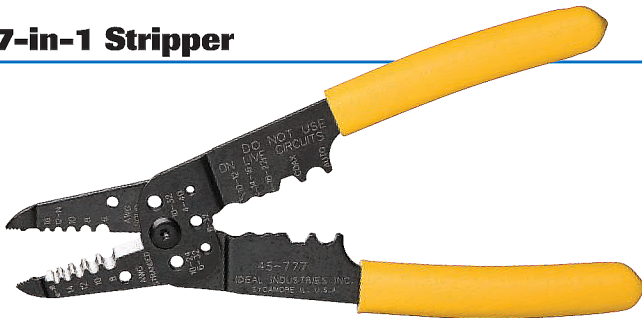


- Versatile, seven-function tool features precision-ground stripping blades, cushioned grips and plier nose
- Strips 8 – 16 AWG solid and 10 – 18 AWG stranded wire
- Crimps bare and insulated terminals for 10 – 22 AWG wire, RG-59 coax connectors and 7 to 8mm auto ignition connectors
- Cuts unhardened wire, bolts and screws (4-40, 6-32, 8-32, 10-24 and 10-32) and reforms threads
- Cuts stranded, solid, Romex® and U.F. wire to 8 AWG
- Reams and de-burrs conduit
- Gauges and loops wire

Description	Cat. No.
7-in-1 Stripper	<b>45-777</b>

Romex® is a registered trademark of Southwire.

## Ringer™ Shielded Cable Stripper

 - Precision stripping for most non-round cable, including extruded Teflon®, Kapton®, Tefzel®, Kynar® and high-temperature insulations
- Spring-loaded head provides even tension
- Heat-treated, stainless-steel blades resist wear
- Fixed blades are sized to insulation thickness, for accurate stripping
- V-notch jaw automatically positions and holds cable
- Wire guide roller maintains stripping head alignment, for square, clean cuts



Description	Blade	Color	Cat. No.
Cable Stripper, 5 Mil insulation, includes blade	K-6492	(Orange)	<b>45-401</b>
Cable Stripper, 8-10 Mil insulation, includes blade	K-6493	(Yellow)	<b>45-402</b>
Cable Stripper, Cable diameters up to 0.12 in.	sold separately	(Blue)	<b>45-400</b>
Cable Stripper, Cable diameters from 0.12 in. to 0.22 in.	sold separately	(Red)	<b>45-403</b>
Cable Stripper, w/"deep V" forcable diameters up to 0.30 in.	sold separately	(Green)	<b>45-404</b>

## Replacement Blades

Cutting Depth	Cat. No.	Cutting Depth	Cat. No.	Cutting Depth	Cat. No.
.0030 in.	<b>K-6491</b>	.0100 in.	<b>K-6497</b>	.0180 in.	<b>K-6503</b>
.0044 in.	<b>K-6492</b>	.0110 in.	<b>K-6498</b>	.0200 in.	<b>K-6504</b>
.0060 in.	<b>K-6493</b>	.0120 in.	<b>K-6499</b>	.0220 in.	<b>K-6505</b>
.0070 in.	<b>K-6494</b>	.0130 in.	<b>K-6500</b>	.0250 in.	<b>45-2108-1</b>
.0080 in.	<b>K-6495</b>	.0140 in.	<b>K-6501</b>		
.0090 in.	<b>K-6496</b>	.0160 in.	<b>K-6502</b>		

Select blade with cutting depth less than insulation thickness.

## Wire Stops



Description	Cat. No.
Up to 2-1/2 in.	<b>LB-825</b>
2-1/2 in. to 5 in.	<b>LB-840</b>

## IDEAL Gripper™



Description	Cat. No.
Slug Remover	<b>45-333</b>

Teflon® and Kapton® are registered trademarks of E.I. duPont de Nemours and Company. Kynar® is a registered trademark of Pennwall.