


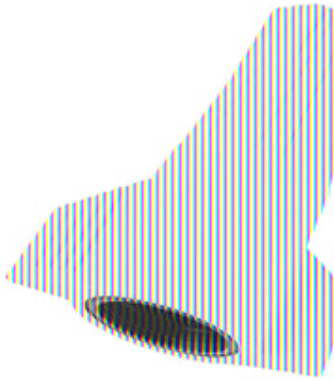

UnderGround® Model 66® Wire Connector, Box of 50



Product Resources

[WeatherProof™ and UnderGround™ Wire Connectors Brochure](#)
(PDF | 1782K)

[Underground® MSDS](#)
(PDF | 152K)

[IDEAL Connector UL Listed Wire Combinations](#)
(PDF | 378K)

Features

- UL Listed to 486D for use with direct burial
- Handles wire sizes from #14 to #6 AWG copper
- Minimum of 3 #12 AWG
- Maximum of 2 #6 & 1 #10 AWG
- Box of 50
- Silicone-based sealant protects against moisture and corrosion
- Easy-to-apply pre-fille twist-on wire connectors
- Live-action, square-wire spring
- Shell rated to 105° C

Models

Description	Catalog #
UnderGround® Model 66® Wire Connector, Box of 50	30-1066

©2014 IDEAL INDUSTRIES, INC. All rights reserved.