


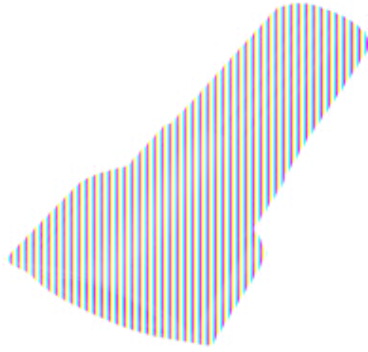

Underground® Model 60® Wire Connector, Box of 1000



Product Resources

[WeatherProof™ and UnderGround™ Wire Connectors Brochure](#)
(PDF | 1782K)

[Underground® MSDS](#)
(PDF | 152K)

[IDEAL Connector UL Listed Wire Combinations](#)
(PDF | 378K)

[UnderGround™ Wire Connectors Specifications Sheet](#)
(PDF | 36K)

Features

- Smallest wet location/direct burial connector with widest wire range
- Handles wire sizes from #20 to #10 AWG copper
- Minimum of 1 #20 with 1 #18
- Maximum of 2 #12 & 1 #10 AWG
- Non-hardening sealant completely seals out moisture to protect against fungus and corrosion
- Sealant is stable down to -40 deg.C
- Box of 1000
- Swept-wing design for comfort
- Live-action, square-wire spring
- Hexagonal shape for standard nutdriver
- No pre-twisting required
- UL Listed and CSA Certified
- Shell rated for 105° C
- Flame-retardant shell

Models

Description	Catalog #
Underground® Model 60® Wire Connector, Box of 1000	30-1360

©2014 IDEAL INDUSTRIES, INC. All rights reserved.