



## Stripmaster Lite, Wire Stripper #16 to #22 AWG

Catalog # 45-671





---

### Features


- Knife-type blades
- cleanly strip wire up to 7/8 in. (22mm)
- Requires one third less hand pressure for each strip
- Eliminates nicking, cutting, and fraying of wire
- Wire gripper holds wire centered in hole

## Stripmaster® and Stripmaster® Lite Wire Strippers

- One-step stripping enhances productivity
- Spring-action motion increases leverage and reduces operator fatigue
- Precision-ground, knife-type blades provide clean, accurate stripping
- Sturdy die cast frame provides long-term durability
- Wire gripper holds wire securely in position
- Stripmaster® Lite designed for smaller hands – 3/4 the size of the standard Stripmaster®

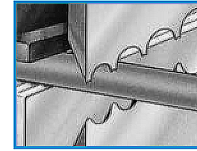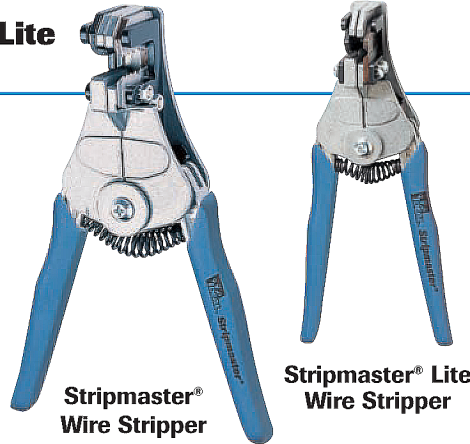

Gripper holds the wire securely in position.

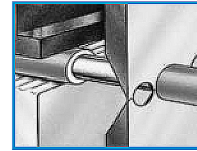

Knife-type stripping blades have form-ground holes which penetrate the insulation like a knife, giving a clean insulation cut.

### Stripmaster® Wire Strippers and Knife-Type Blades



Specifications — Stripping Hole Diameter (Inches)													Cat. No.	Replacement Blades (Pair) Cat. No.	
Wire Size AWG															
6	8	10	12	14	16	18	20	22	24	26	28	30			
	.159	.141	.106											45-090* or 45-290**	L-4419
		.144	.105	.085	.073	.073								45-091	L-4420
		.144	.113	.090	.072	.061	.048	.048						45-092* or 45-292**	L-4421
				.090	.072	.061	.039	.039						45-093	L-4422
.230	.198													45-096	L-4453
					.072	.061	.048	.039	.032	.026				45-097	L-4994
							.048	.039	.032	.026	.021	.016		45-098	L-5361
	.198	.167			.062	.055								45-099	L-8763

 
\*Boxed \*\*Blister Card Tolerances +.001 -.005

### Stripmaster® Lite Wire Strippers and Knife-Type Blades

Specifications — Stripping Hole Diameter (Inches)													Cat. No.	Replacement Blades (Pair) Cat. No.	
Wire Size AWG															
12	14	16	18	20	22	24	26	28	30	16/18	20/22	Cutting Edge			
		.072	.061	.048	.039									45-671	LB-1001
						.032	.026	.021	.016					45-672	LB-1002
.113	.090	.072	.061 (All Stranded wire)											45-673	LB-1003
.096	.085	.073	.061 (12 & 14 Solid wire, 16 & 18 Stranded wire)											45-674	LB-1004
										.072	.048	.250 Wide		45-675	LB-1005

Tolerances +.001 -.005

### Coax Stripmaster® Wire Strippers and Blades



Description	Coax Cable Type (RGU)	Repl. Blade Cat. No.	Cat. No.
Coax Stripmaster® for RG-6	RG-6	LB-740	45-262
Coax Stripmaster® for RG-58	RG-58	LB-742	45-264
Coax Stripmaster® for RG-59	RG-59	LB-743	45-265
Coax Stripmaster® for RG-62	RG-62	LB-744	N/A
Coax Stripmaster® for RG-6 QuadShield	RG-6 QuadShield	LA-3953	45-282

Coaxial Cables: two-step strip for termination, jacket and dielectric.

Replacement Frame Assemblies	Cat. No.
For Stripmaster® Wire Strippers	L-5620
For Stripmaster® Lite Wire Strippers	LB-1421

### Stripmaster® Wire Strippers with Rectangular Holes



Description	Cat. No.	Replacement Blades (Pair) Cat. No.
For Flat Telephone Cable (.60 in. or 1.52mm)	N/A	LB-1155
For European Flat Lamp Cord	45-089	L-8762
For SP-SPT Lamp Cord	45-095*	L-4452

\*Also strips 2- and 3-conductor low-voltage wire used in G.E. and Touchplate remote control wiring system.

Optional Accessories	Cat. No.
Transparent Adjustable Wire Stop (for Stripmaster® Wire Strippers)	L-5270
Transparent Adjustable Wire Stop (for Stripmaster® Lite Wire Strippers)	LB-1195
Replacement Moveable Gripper	L-1953