

Ø 171X51 mm


SUNON

**Alveolate Motor**  
**203-239 CFM**




Model	P/N	Bearing	Rating Voltage (VAC)	Freq. (Hz)	Power Current (AMP)	Power Consumption (WATTS)	Speed (RPM)	Air Flow (CFM)	Static Pressure (Inch-H <sub>2</sub> O)	Noise (dBA)	Weight (g)
A1175-HBL	TC,R,GN	○ BALL	115	50/60	0,22/0,23	25/27	2800/3200	203/239	0,62/0,69	51/58	908
A1175-HBT	TC,R,GN	○ BALL	115	50/60	0,22/0,23	25/27	2800/3200	203/239	0,62/0,69	51/58	908
A2175-HBL	TC,R,GN	○ Sleeve	220-240	50/60	0,11/0,11	25/26	2800/3200	203/239	0,62/0,69	51/58	908
A2175-HBT	TC,R,GN	○ Sleeve	220-240	50/60	0,11/0,11	25/26	2800/3200	203/239	0,62/0,69	51/58	908

Frame : Aluminum alloy

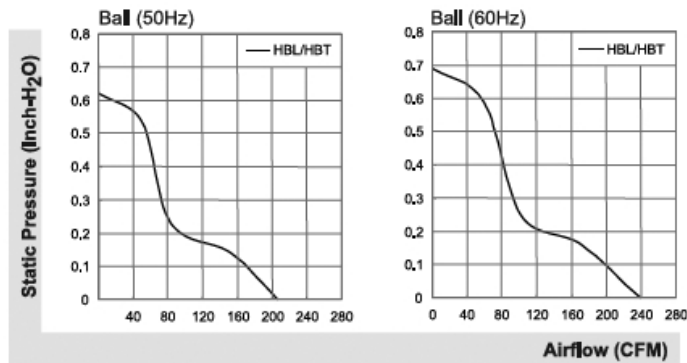

UNITS:mm

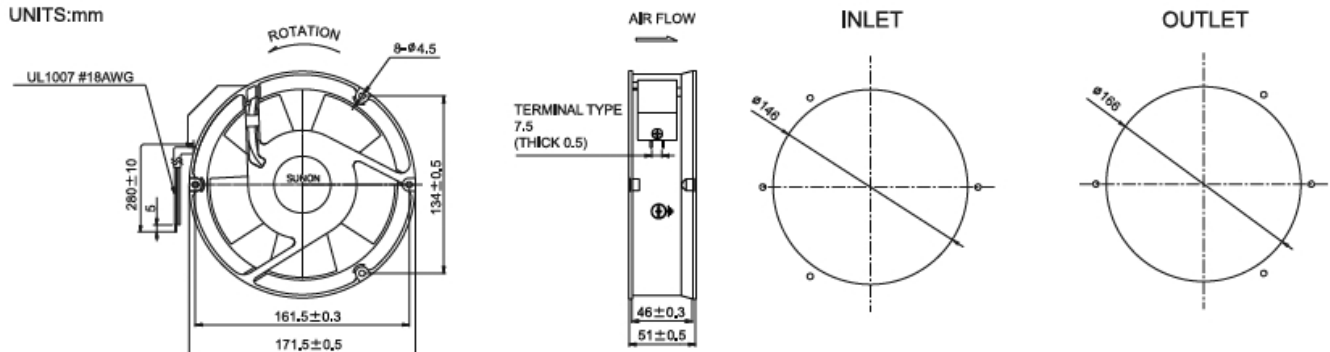

\*All model could be customized on voltage or any other requirements to fit your need.

\*Specifications subject to change without notice. Please Visit SUNON web site at <http://www.sunon.com> for update information.