

GB/TB Series



- Description** Lamp and Tube Headers
- Electrical Rating** • 300 Volts, 10 Amps
- Construction** **Contacts** • Brass, Bright Tin Plated
Molding • High Temperature Thermoset
- Agency Approvals** • UL recognized, File No. E60008
• CSA certified, File No. LR29513
• ROHS



GB/TB Series Ordering Code

Part #	Description
GB08	8 pin lamp header (Fig. 1)
TB08	8 pin tube header (Fig. 2)

Figure 1

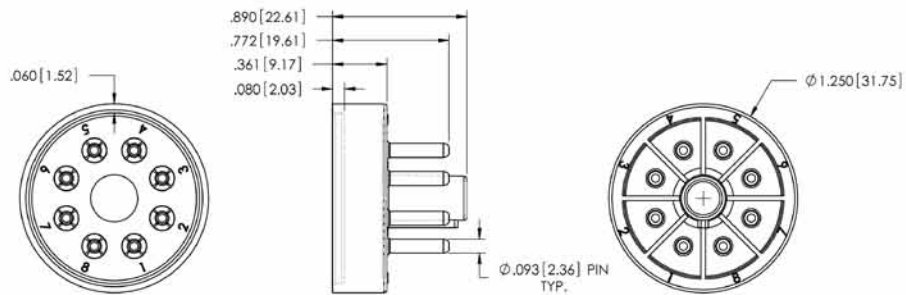


Figure 2

