




Cable Ties Polyamide 6.6 standard T18R

T-Series in PA66 natural, Article number: 111-01919

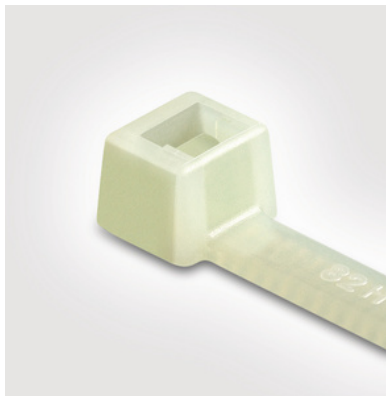

Features

- Available in a wide range of material and sizes
- Made from 100 % high quality plastic, allows for good recycling
- Inside serration for a strong hold onto bundles
- Easy application either manually or with a processing tool
- Simply to insert due to bent tail

Certifications & Approvals



Application

These cable ties are used for routing, bundling and securing of cables, pipes and hoses.

T-Series in PA66 natural is suitable for following markets and industries



Base Data

Application Tool	MK20, MK3SP, MK3PNSP2, EVO7
Colour	Natural (NA)
Description Short (BMEcat) (max. 150 characters)	Cable Tie 100x2.5 natural
Fixation Method (FF)	None
Identification Plate Position	none
Manufacturer Type	T18R PA66 NA 100
Pack Cont.	100 pcs.
Product Family	T-Series in PA66 natural
Product Group	Cable Ties Polyamide 6.6 standard
Releasable Closure (Yes/No)	No
Tie Closure	plastic pawl

Product Dimensions

Bundle Ø max.	22 mm
Bundle Ø min.	1.5 mm
Length (L)	100.0 mm
Min.Tensile Strength (N)	80 N
Thickness (T)	1.0 mm
Width (W)	2.5 mm

Material and Specifications

ELV compliant Dir. Art. 4 (2)	YES
Flammability	UL94 V2
Halogenfree	Yes
Hazardous goods	No
Material	Polyamide 6.6 (PA66)
Operating Temperature	-40 °C to +85 °C, (+105 °C, 500 h)
REACH compliant Regu. Art. 33	YES
Specifications	UL ANSI/UL 746B, UL ANSI/UL 1565, UL ANSI/UL 62275, DNV GL IEC 62275:2006
UL OCD link	
UL-File Number	E85319

Logistics and Packaging

EAN / GTIN	4031026104225
Packaging 1 - Height (m)	0.014 m
Packaging 1 - Length (m)	0.14 m
Packaging 1 - Qty	100
Packaging 1 - Type	Bag
Packaging 1 - Volume (m³)	0.00013 m³
Packaging 1 - Weight (kg)	0.033 kg
Packaging 1 - Width (m)	0.065 m
Packaging 2 - Height (m)	0.17 m
Packaging 2 - Length (m)	0.286 m
Packaging 2 - Qty	8000
Packaging 2 - Type	Carton
Packaging 2 - Volume (m³)	0.0088 m³
Packaging 2 - Weight (kg)	2.77 kg
Packaging 2 - Width (m)	0.18 m
Packaging 3 - Height (m)	0.371 m
Packaging 3 - Length (m)	0.414 m
Packaging 3 - Qty	32000
Packaging 3 - Type	Carton
Packaging 3 - Volume (m³)	0.0488 m³
Packaging 3 - Weight (kg)	11.7 kg

7/12/2016

Cable Ties Polyamide 6.6 standard T18R (111-01919) | HellermannTyton

Packaging 3 - Width (m)	0.318 m
Packaging 4 - Length (m)	1.2 m
Packaging 4 - Qty	576000
Packaging 4 - Type	pallet
Packaging 4 - Weight (kg)	231.6 kg
Packaging 4 - Width (m)	0.8 m
Quantity per	Bag
Weight	0.028 kg

More Information

ETIM 5.0	EC000046
ETIM 6.0	EC000046

Accessories



EVO7
110-70129
Manual Tensioning Tool
with Plastic Housing



EVO7SP
110-70130
Manual Tensioning Tool
Plastic Housing



MK20
110-20006
Manual Tensioning Tool for
Cable Ties, simple version



MK3SP
110-03500
Manual Tensioning Tool
with Metal Housing



MK3PNSP2
110-03400
Pneumatic Tensioning Tool
with Metal Housing



MK7P
110-07100
Pneumatic Tensioning Tool
with Plastic Housing


Similar products



Q18R
109-00001
Cable Ties with open head




T18R
112-01819
Cable Ties Polyamide 6.6
standard

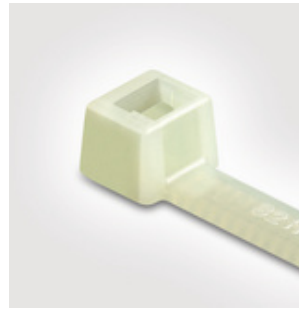


T18R
111-00642
Cable Ties Polyamide 6.6
standard



T18R
111-00643
Cable Ties Polyamide 6.6
standard

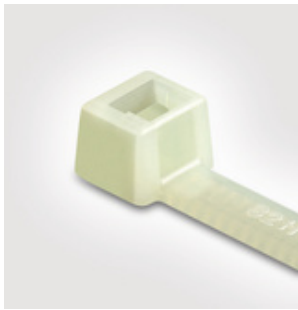

T18S
111-02800
Cable Ties Polyamide 6.6
standard

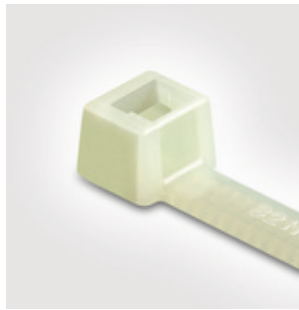

T18S
111-02805
Cable Ties Polyamide 6.6
standard