



## Electrical Commercial and Industrial


- Products
- Documentation & Literature
- News & Tradeshows
- Support

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) > \_\_\_\_\_

# 3M™ Scotchlok™ Butt Connector Nylon Insulated Grease Filled, 100/bottle, MNG14BCM-A

3M ID 80611466402 UPC# 00051128589946 3M Product Number MNG14BCM-A

- Print
- Share

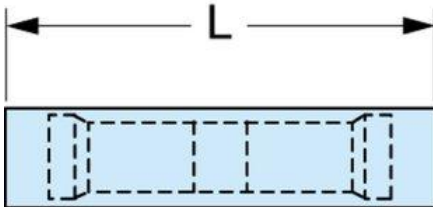

Butt Connector Nylon Insulated Grease Filled, 100/bottle, MNG14BCM-A

- Overview
- Documentation

### Specifications

Barrel Inside Diameter	0.090 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Scotchlok
Conductor Sizes	16 - 14 AWG
Insulation Material	Nylon with Insulation Grip
Length (L)	1.06 Inch
Maximum Insulation Outer Diameter	0.170 Inch
Packaging	100 per bottle
Terminal Style	Moisture Resistant
Terminal Type	Butt
Thickness	0.030 Inch

