




## Electrical Commercial and Industrial

# 3M™ Highland™ Nylon Fully Insulated Female Disconnect Terminal FDI14-250Q, AWG 16-14, 25/bag

UPC# 00051128600016 3M Product Number FDI14-250Q 3M ID 80611602626

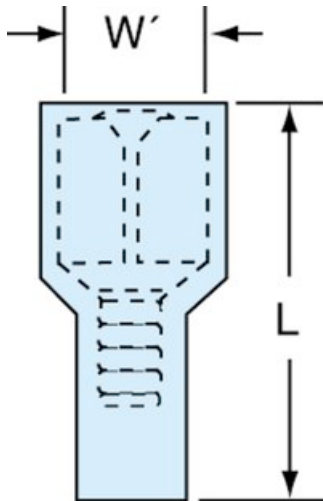

This female disconnect accepts a wire range of 16-14 AWG, a .250 and has a case quantity of 10 bags.

Like

Be the first of your friends to like this.

Overview

Support

### Specifications

Agency Approvals	UL and CSA
Barrel Inside Diameter	0.08 Inch
Barrel Length	0.25 Inch
Barrel Style	Butted
Brand	Highland
Conductor Sizes	16 - 14 AWG
CSA File Number	LR22190
Diameter (D)	0.23 Inch
Fastener Orientation	Female
Insulation Material	Nylon
Length (L)	0.87 Inch

<b>Mates with Male Tab Width (W')</b>	0.25 Inch
<b>Maximum Insulation Outer Diameter</b>	0.145 Inch
<b>Packaging</b>	25 per bag
<b>Pad Width</b>	0.25 Inch
<b>Terminal Style</b>	Fully Insulated
<b>Terminal Type</b>	Disconnect
<b>Thickness</b>	0.032 Inch
<b>UL File Number</b>	E70512
<b>Width (W)</b>	0.37 Inch