


6GK1901-1BB10-2AE0 IE FC RJ45 PLUG 180 2X2

Technical Data

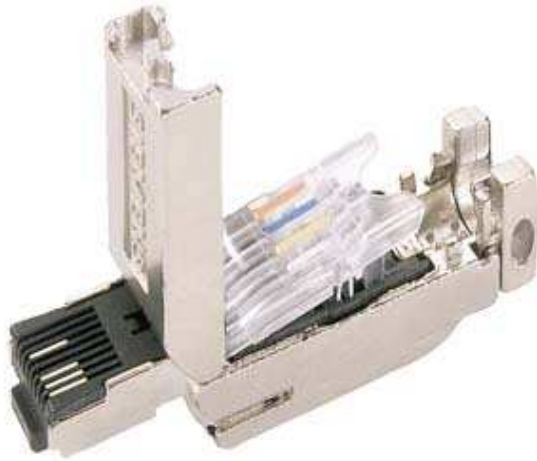

IE FC RJ45 PLUG 180 2X2, RJ45 PLUG CONNECTOR (10/100MBIT/S) WITH RUGGED METAL HOUSING AND FC CONNECTING METHOD, FOR IE FC CABLE 2X2 180 DGR CABLE OUTLET 1 PACK = 50 PCS

Transfer rate

- | | |
|--|------------------------------------|
| <ul style="list-style-type: none"> ● 1 / for Industrial Ethernet ● 2 / for Industrial Ethernet | <p>10 Mbit/s</p> <p>100 Mbit/s</p> |
|--|------------------------------------|

Interfaces

- | | |
|--|------------------------------|
| <p>Number of electrical connections</p> <ul style="list-style-type: none"> ● for Industrial Ethernet FC TP cables ● for network components and terminal equipment <p>Design of the electrical connection / FastConnect</p> | <p>4</p> <p>1</p> <p>Yes</p> |
|--|------------------------------|

Mechanical data

material / of the housing	metal
---------------------------	-------

Design, dimensions and weight

Width	13.7 mm
Height	16 mm
Depth	55 mm
Net weight	35 g

Permitted ambient conditions

- | | |
|---|---|
| <p>Ambient temperature</p> <ul style="list-style-type: none"> ● during operating ● during storage ● during transport <p>Relative humidity</p> <ul style="list-style-type: none"> ● at 25 °C / without condensation / during operating / maximum | <p>-40...+70 °C</p> <p>-40...+80 °C</p> <p>-40...+80 °C</p> <p>95 %</p> |
|---|---|

Protection class IP	IP20
Product properties, functions, components / general	
Product feature / [not supplied - silicon-free]	Yes
Composant produit	
• décharge de traction	Yes
Standards, specifications, approvals	
Verification of suitability	
• RoHS conformity	Yes
• UL-registration	Yes
letzte Änderung:	May 14, 2012