

Multi-Hole Bushings

Chloroprene multi-hole bushing

Fits SAB
Metric, PG, or NPT
cord grips



Multi-hole bushings are ideal for when there is limited space on a control cabinet or when you have multiple smaller cables that need to be secured. They are made of black chloroprene and, when used with a SAB cord grip, will provide an excellent seal.

Material: Chloroprene (CR)
Color: Black

Technical data:



Part Number	Clamping Range		CG 100 Plastic Cord Grip			CG 300 Metal Cord Grip			Hole Quantity	Hole Diameter Ø inches	Outer Dia. D inches	Height h inches
	inches	mm	PG	Metric	NPT	PG	Metric	NPT				
MHB-02	0.157 - 0.315	4 - 8	PG 9	M16C	-	PG 9	M16	NPT 3/8"	2	0.118	0.429	0.276
MHB-01	0.157 - 0.315	4 - 8	PG 9	M16C	-	PG 9	M16	NPT 3/8"	2	0.157	0.429	0.276
MHB-03	0.157 - 0.315	4 - 8	PG 9	M16C	-	PG 9	M16	NPT 3/8"	4	0.118	0.429	0.276
MHB-07	0.197 - 0.394	5 - 10	PG 11	M16	NPT 3/8"	PG 11	M16C	NPT 3/8"C	2	0.118	0.539	0.409
MHB-04	0.197 - 0.394	5 - 10	PG 11	M16	NPT 3/8"	PG 11	M16C	NPT 3/8"C	2	0.157	0.539	0.409
MHB-05	0.197 - 0.394	5 - 10	PG 11	M16	NPT 3/8"	PG 11	M16C	NPT 3/8"C	2	0.177	0.539	0.409
MHB-08	0.197 - 0.394	5 - 10	PG 11	M16	NPT 3/8"	PG 11	M16C	NPT 3/8"C	2	0.197	0.539	0.409
MHB-09	0.197 - 0.394	5 - 10	PG 11	M16	NPT 3/8"	PG 11	M16C	NPT 3/8"C	3	0.157	0.539	0.409
MHB-14	0.236 - 0.472	6 - 12	PG 13.5	M20	NPT 1/2"	PG 13.5	M20	NPT 1/2"	2	0.197	0.630	0.331
MHB-10	0.236 - 0.472	6 - 12	PG 13.5	M20	NPT 1/2"	PG 13.5	M20	NPT 1/2"	2	0.236	0.630	0.331
MHB-11	0.236 - 0.472	6 - 12	PG 13.5	M20	NPT 1/2"	PG 13.5	M20	NPT 1/2"	3	0.157	0.630	0.331
MHB-12	0.236 - 0.472	6 - 12	PG 13.5	M20	NPT 1/2"	PG 13.5	M20	NPT 1/2"	3	0.197	0.630	0.331
MHB-13	0.236 - 0.472	6 - 12	PG 13.5	M20	NPT 1/2"	PG 13.5	M20	NPT 1/2"	4	0.118	0.630	0.331
MHB-15	0.236 - 0.472	6 - 12	PG 13.5	M20	NPT 1/2"	PG 13.5	M20	NPT 1/2"	4	0.157	0.630	0.331
MHB-19	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	2	0.157	0.709	0.366
MHB-16	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	2	0.236	0.709	0.366
MHB-76	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	2	0.256	0.709	0.366
MHB-17	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	2	0.276	0.709	0.366
MHB-18	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	3	0.157	0.709	0.366
MHB-77	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	3	0.220	0.709	0.366
MHB-78	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	3	0.236	0.709	0.366
MHB-20	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	4	0.197	0.709	0.366
MHB-79	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	4	0.236	0.709	0.366
MHB-23	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	5	0.157	0.709	0.366
MHB-80	0.394 - 0.551	10 - 14	PG 16	M20C	NPT 1/2"C	PG 16	M20C	NPT 1/2"C	6	0.157	0.709	0.366
MHB-35	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	2	0.236	0.803	0.421
MHB-37	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	3	0.197	0.803	0.421
MHB-36	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	3	0.236	0.803	0.421
MHB-38	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	3	0.276	0.803	0.421
MHB-39	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	4	0.197	0.803	0.421
MHB-40	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	5	0.157	0.803	0.421
MHB-41	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	6	0.157	0.803	0.421
MHB-42	0.433 - 0.669	11 - 17	-	M25C	-	-	M25RC	-	7	0.118	0.803	0.421
MHB-25	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	2	0.260	0.902	0.480
MHB-26	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	2	0.276	0.902	0.480
MHB-27	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	2	0.315	0.902	0.480
MHB-28	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	2	0.354	0.902	0.480
MHB-29	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	3	0.260	0.902	0.480
MHB-81	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	3	0.276	0.902	0.480


Contact SAB, if you have a different SAB gland then above.

Accessories

Multi-Hole Bushings

Chloroprene multi-hole bushing

Fits SAB
Metric, PG, or NPT
cord grips

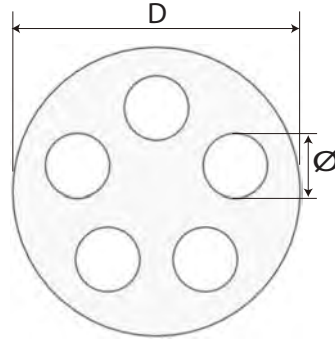

Part Number	Clamping Range		CG 100			CG 300			Hole Quantity	Hole Diameter Ø mm	Outer Dia. D inches	Height h inches
	inches	mm	PG	Metric	NPT	PG	Metric	NPT				
MHB-30	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	3	0.315	0.480	0.480
MHB-32	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	4	0.260	0.480	0.480
MHB-33	0.512 - 0.709	13 - 18	PG 21	M25	NPT 3/4"	PG 21	M25C, M32	NPT 3/4"	4	0.276	0.480	0.480
MHB-54	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	2	0.276	0.559	0.559
MHB-52	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	2	0.315	0.559	0.559
MHB-55	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	2	0.354	0.559	0.559
MHB-53	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	3	0.315	0.559	0.559
MHB-58	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	4	0.236	0.559	0.559
MHB-59	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	4	0.276	0.559	0.559
MHB-56	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	4	0.315	0.559	0.559
MHB-57	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	5	0.236	0.559	0.559
MHB-60	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	6	0.197	0.559	0.559
MHB-61	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	6	0.236	0.559	0.559
MHB-63	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	8	0.157	0.559	0.559
MHB-64	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	8	0.197	0.559	0.559
MHB-62	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	9	0.118	0.559	0.559
MHB-65	0.591 - 0.826	15 - 21	-	M32C	-	-	M32RC	-	9	0.157	0.559	0.559
MHB-43	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	2	0.315	0.551	0.551
MHB-44	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	2	0.354	0.551	0.551
MHB-45	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	3	0.295	0.551	0.551
MHB-47	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	4	0.315	0.551	0.551
MHB-48	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	5	0.335	0.551	0.551
MHB-49	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	6	0.236	0.551	0.551
MHB-50	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	6	0.295	0.551	0.551
MHB-51	0.709 - 0.984	18 - 25	PG 29	M32	NPT 1"	PG 29	M32C, M40	NPT 1"	6	0.197	0.551	0.551
MHB-66	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	2	0.394	0.669	0.669
MHB-67	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	3	0.394	0.669	0.669
MHB-68	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	4	0.315	0.669	0.669
MHB-69	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	5	0.315	0.669	0.669
MHB-70	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	5	0.354	0.669	0.669
MHB-71	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	6	0.276	0.669	0.669
MHB-72	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	8	0.236	0.669	0.669
MHB-73	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	9	0.276	0.669	0.669
MHB-74	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	10	0.236	0.669	0.669
MHB-75	0.748 - 1.102	19 - 28	-	M40C	-	-	M40RC	-	12	0.209	0.669	0.669
MHB-82	0.866 - 1.260	22 - 32	PG 36	M40	-	PG 36	M40C, M50	NPT 1 1/4"	5	0.354	0.661	0.661
MHB-83	0.866 - 1.260	22 - 32	PG 36	M40	-	PG 36	M40C, M50	NPT 1 1/4"	8	0.315	0.661	0.661

Contact SAB, if you have a different SAB gland then above.