



Brilliance by design

SloanLED™

Panel Mount, Non-Relampable LED Snap Mount Indicator


www.SloanLED.com

MODEL 500

The 500 Model incorporates a non-relampable T-1 3/4 size LED in a choice of colors. For panel mounting through a 1/2" (0.500") dia. hole; snap fits, needs no mounting hardware. Transparent lens for maximum viewing angle. Supplied standard with 6" wire leads, although any length may be ordered. Optional .250 QC terminals may be specified. Can be supplied with or without built in current limiting resistor.



Suggested mounting diameter 1/2"

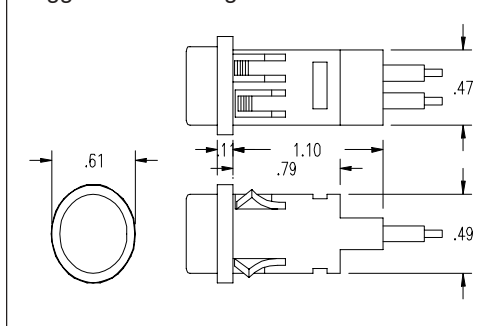

FEATURES

- Snaps mounts in 1/2" (0.500") diameter hole; needs no mounting hardware.
- Supplied standard with 6" wire leads, unless otherwise specified.
- Can be supplied with .250 QC terminals.
- Uses T-1 3/4 LED.
- For operation from 5V., 12V., 24V., or 28V sources, with built-in resistor.
- Transparent lens for maximum viewing angle.
- Fits 1/8" panel thickness.

NOTE:
For Voltage/Current Specs, see page A-1.
LEDs continuous forward current = 20 mA

500

HOW TO ORDER: Incandescent

0.187" QC Termination		6" Lead Termination	
Voltage	Model No.	Voltage	Model No.
5vdc	5001-5XQC	5vdc	5001-5X
12vdc	5001-12XQC	12vdc	5001-12X
24vdc	5001-24XQC	24vdc	5001-24X
28vdc	5001-28XQC	28vdc	5001-28X

Where the 'X' appears insert: 1-Red, 2-Green, 3-Yellow, 4-Amber, 5-Ultra Green, 6-Ultra Blue, 7-Pure White

HOW TO ORDER: LED

0.250" QC Termination		6" Lead Termination	
Voltage	Model No.	Voltage	Model No.
5vdc	5002-5XQC	5vdc	5002-56X
12vdc	5002-12XQC	12vdc	5002-126X
24vdc	5002-24XQC	24vdc	5002-246X
28vdc	5002-28XQC	28vdc	5002-286X

Where the 'X' appears insert: 1-Red, 2-Green, 3-Yellow, 4-Amber, 5-Ultra Green, 6-Ultra Blue, 7-Pure White