

Automation Technology > Power supplies > Power supply SITOP > Expansion modules > Buffer module

## 6EP1961-3BA01 SITOP BUFFER MODULE

Technical / CAx data


Technical Data  CAx data



SITOP BUFFER MODULE FOR  
6EP1X3X-3BAX0 BUFFERING TIME  
100 MS TILL 10 S DEPENDENT UPON  
LOAD

<b>Technical specifications</b>	
<b>Input</b>	
Supply voltage / for DC / rated value	24 V
<b>Mains buffering</b>	
<b>Output</b>	
Output current / nominal value	40 A
<b>Efficiency</b>	
<b>Protection and monitoring</b>	
<b>Signaling</b>	
<b>Interface</b>	
Product component / PC interface	No
Design of the interface	without
<b>Safety</b>	
Galvanic isolation / between entrance and outlet	Yes
Verification of suitability / UL-registration	Yes
Verification of suitability / CE mark	Yes
Protection class IP	IP20
<b>EMC</b>	
<b>Operating data</b>	
Ambient temperature / in operation	0...60 °C
Ambient temperature / on transport	-40...+85 °C
Ambient temperature / in storage	-40...+85 °C
<b>Mechanics</b>	
Design of the electrical connection	screw-type terminals

Width / of the housing	70 mm
Height / of the housing	125 mm
Depth / of the housing	125 mm
Installation width	70 mm
Required spacing / top	50 mm
Required spacing / bottom	50 mm
Required spacing / left	0 mm
Required spacing / right	0 mm
Net weight	1.2 kg
Product feature / of the housing / housing for side-by-side mounting	Yes

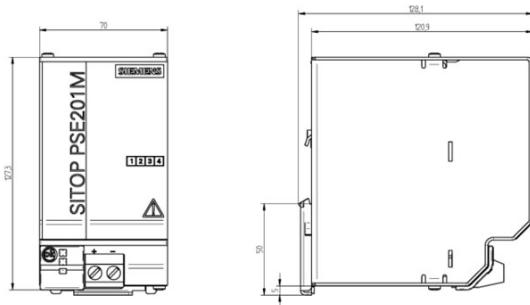

**letzte Änderung:**

May 28, 2012