




## PRODUCT SPECIFICATION

**CATALOG NUMBER:** See table below  
**DESCRIPTION:** Outdoor use SJTW cord set  
**APPROVALS:** UL Listed and CSA Certified, or UL/CUL Listed Outdoor Use Cord Set

### CONSTRUCTION PARAMETERS:

Conductor: See table below  
 Jacket material: PVC  
 Overall cable O.D. (nom): See table below  
 Cord rating: Hard Usage per the National Electrical Code  
 Cable legend: Indent print  
 Cable color: See table below

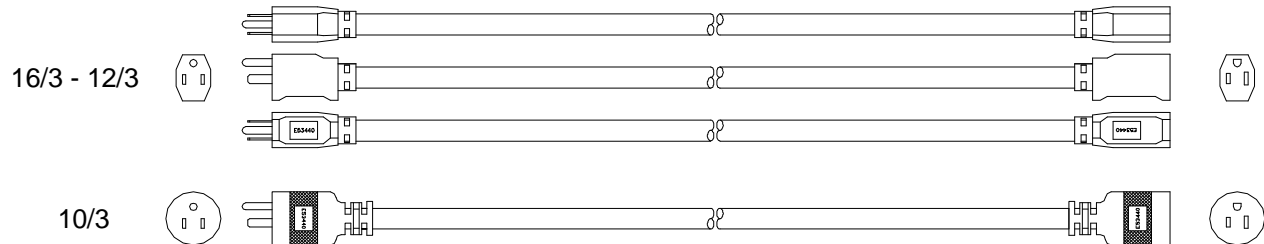

*Note: Plug and connector style may vary*

Attachment plug configuration: NEMA 5-15P  
 Cord connector configuration: NEMA 5-15R  
 Plug and connector material: PVC  
 Plug and connector color: Same as cable color

### ELECTRICAL PROPERTIES:

Cable temperature rating: -40 to +60 °C  
 Nominal operating voltage: 125 VAC  
 Maximum operating current: See table below

Catalog no.	Length	Color	Conductor	Cable O.D. (nom)	Current rating
0260	8 ft	Black	16/3 26/30 BC	0.315 in	13A
0265	8 ft	Orange			
990261	15 ft	Black			
0266	15 ft	Orange			
0267	25 ft	Orange			
0268	50 ft	Orange			
0269	100 ft	Orange			
0625	25 ft	Orange	14/3 41/30 BC	0.352 in	15A
0626	50 ft	Orange			13A
0627	100 ft	Orange			15A
0528	25 ft	Orange	12/3 65/30 BC	0.420 in	15A
0529	50 ft	Orange			
0530	100 ft	Orange	10/3 104/30 BC	0.567 in	15A
0517	50 ft	Orange			
0518	100 ft	Orange			

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part. We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is proprietary intellectual property of Coleman Cable Systems. Any information contained herein shall not be disclosed to any party without written consent of Coleman Cable Systems.