




Electrical Commercial and Industrial

[United States](#) > [All 3M Products](#) > [Market Segments](#) > [Electronics, Electrical, and Communications](#) > [Electrical Products](#) > [Electrical Commercial and Industrial](#) > [Products](#) >

3M™ Scotchlok™ Butt Connector Nylon Insulated Grease Filled, 100/bottle, MNG18BCM-A

3M ID 80611466394 UPC# 00051128589939 3M Product Number MNG18BCM-A

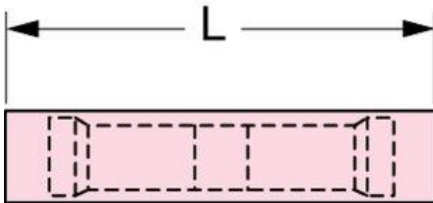

Butt Connector Nylon Insulated Grease Filled, 100/bottle, MNG18BCM-A

Overview

Documentation

Specifications

| | |
|-----------------------------------|----------------------------|
| Barrel Inside Diameter | 0.070 Inch |
| Barrel Length | 0.25 Inch |
| Barrel Style | Butted |
| Brand | Scotchlok |
| Conductor Sizes | 22 - 18 AWG |
| Insulation Material | Nylon with Insulation Grip |
| Length (L) | 1.02 Inch |
| Maximum Insulation Outer Diameter | 0.145 Inch |
| Packaging | 100 per bottle |
| Terminal Style | Moisture Resistant |
| Terminal Type | Butt |
| Thickness | 0.030 Inch |