 

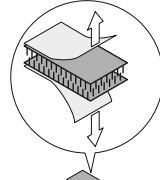
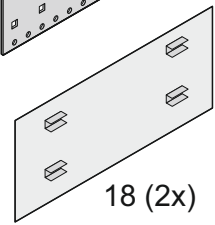
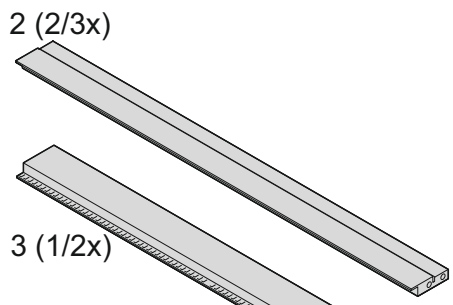
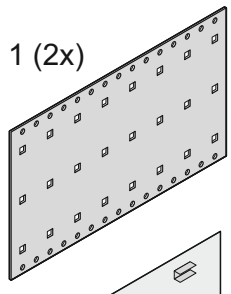


07/2013
☎ telephone: +49(0)70 82 7 94 200


pentairequipmentprotection.com
☎ telephone: +49(0)70 82 7 94-0

Langenalber Straße 96 - 100
• D-75334 Straubenhardt



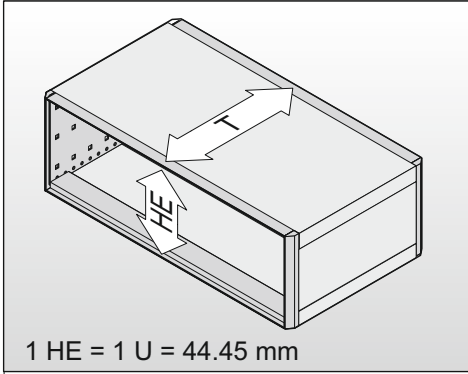


- Torx 20
M4 x 10
9 (8x)
- Torx 20
M4 x 14
10 (8x)
- Torx 20
M4 x 8
17 (8x)

ratiopac PRO

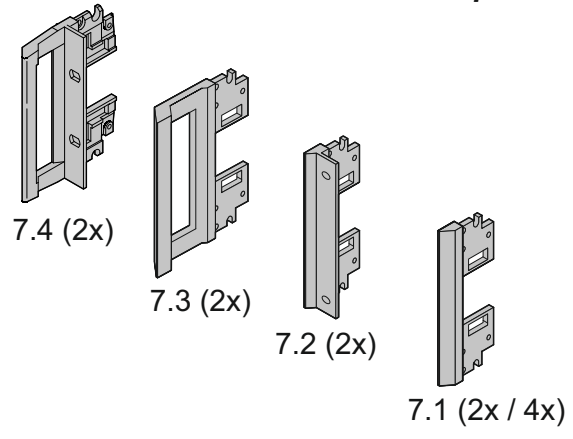


ratiopac PRO-air

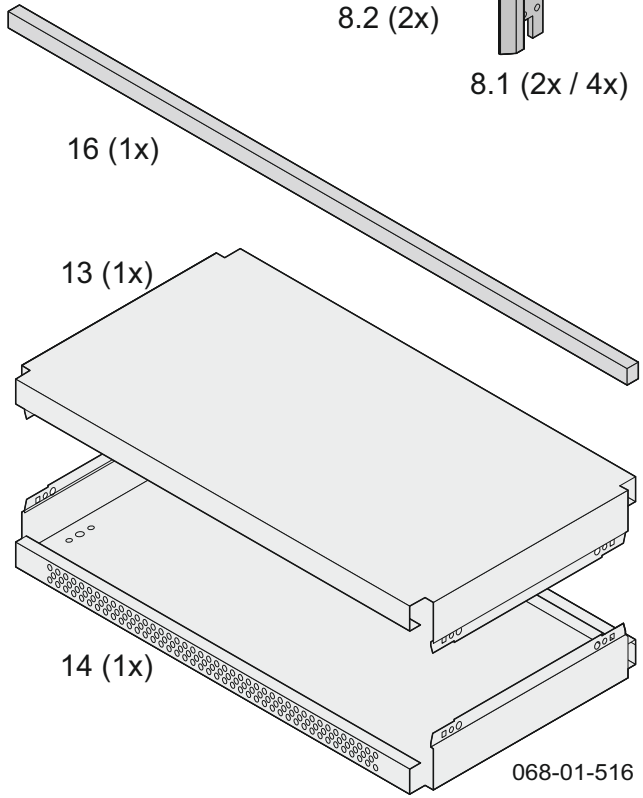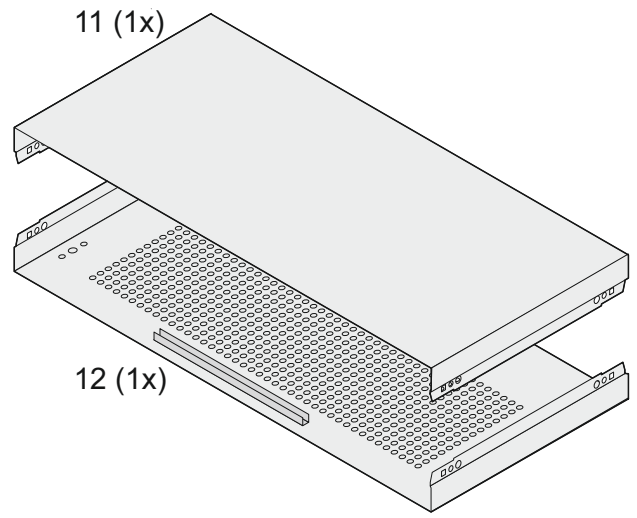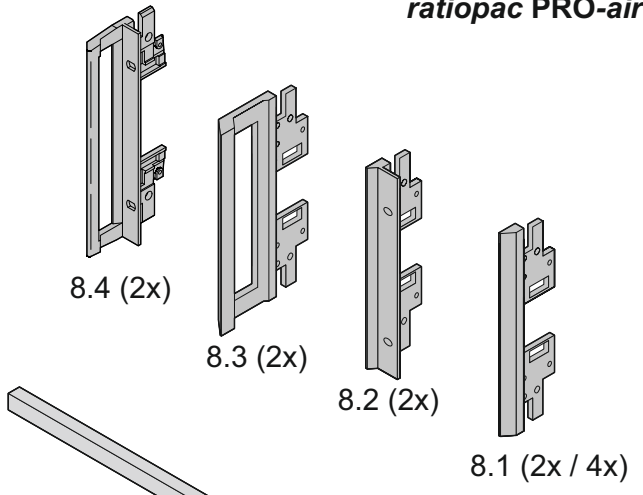

068-01-516

Demontage
Disassembly
Démontage

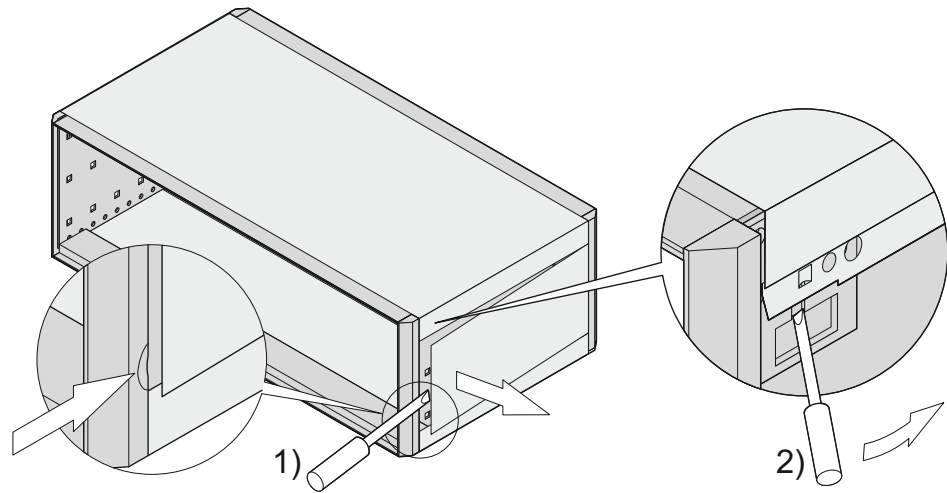

A





3 HE / U

4 HE / U

5 HE / U

6 HE / U

ratiopacPRO

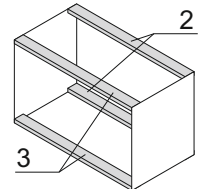
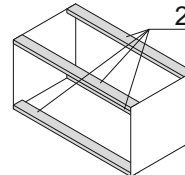
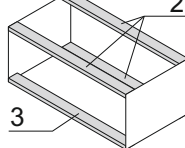
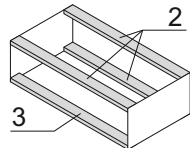


ratiopacPRO-air

4 HE / U

5 HE / U



7 HE / U

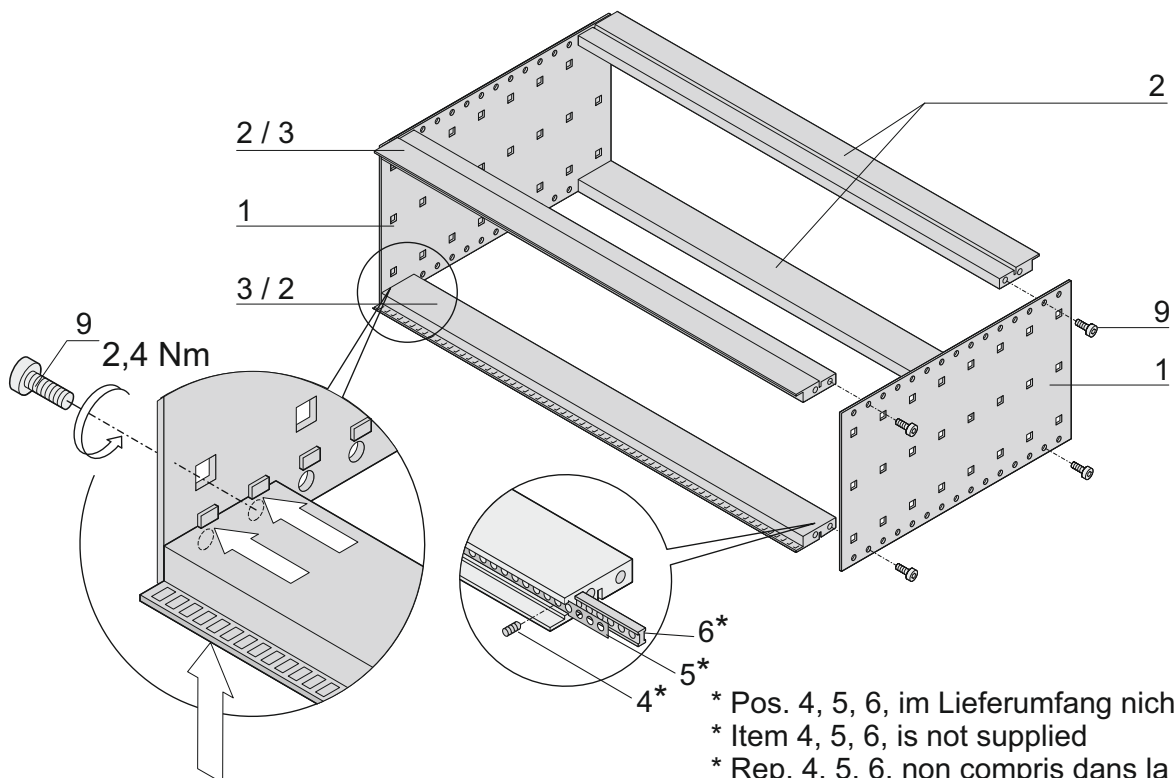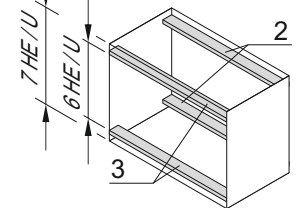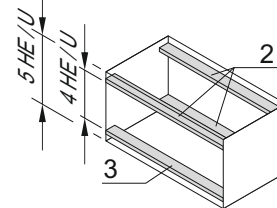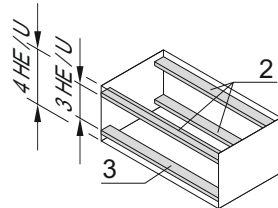

* Pos. 4, 5, 6, im Lieferumfang nicht enthalten
* Item 4, 5, 6, is not supplied
* Rep. 4, 5, 6, non compris dans la livraison



B1

ratiopac PRO

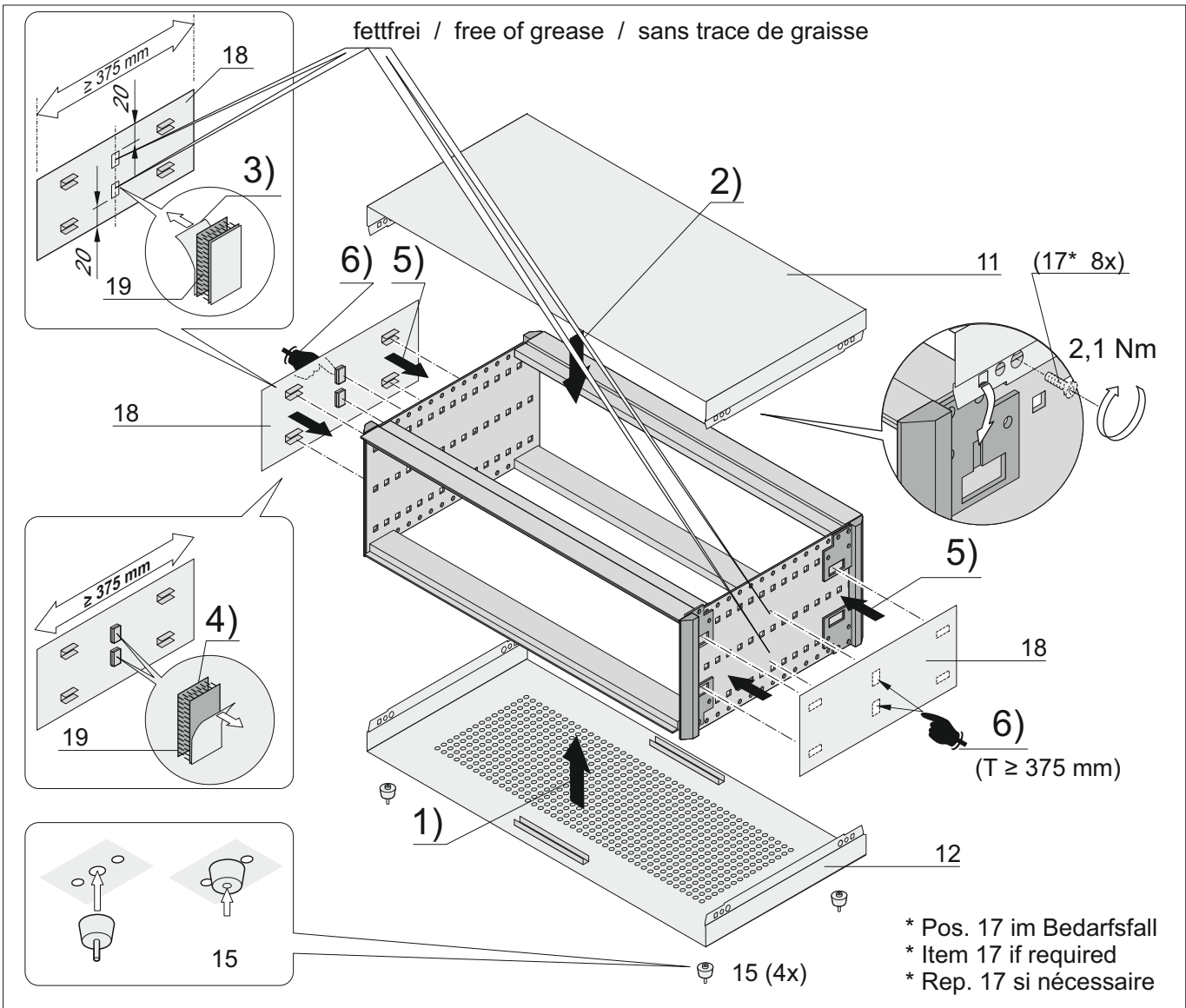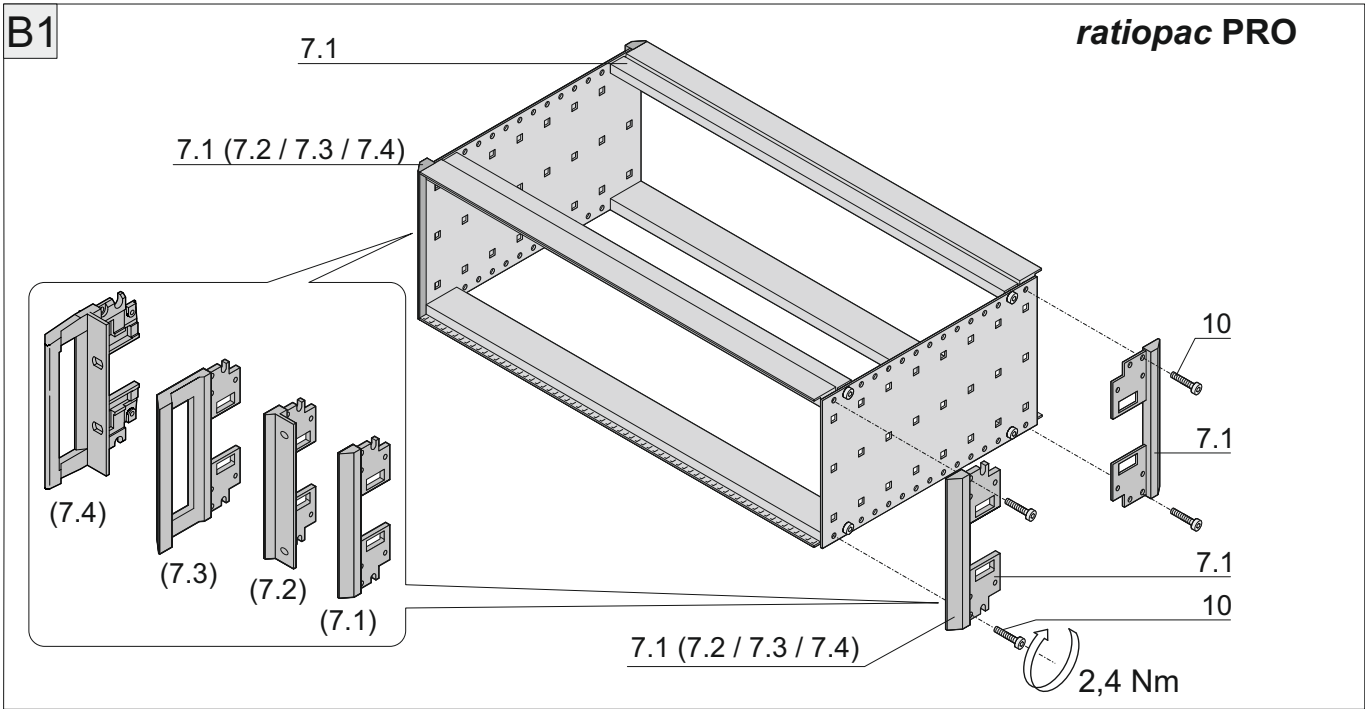


B2




ratiopac PRO-air

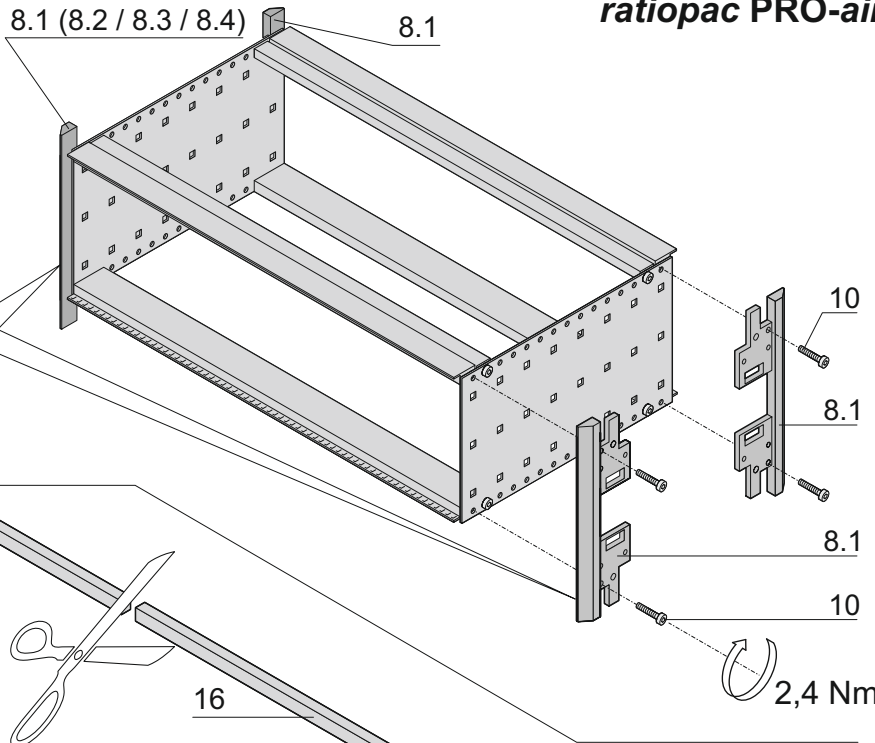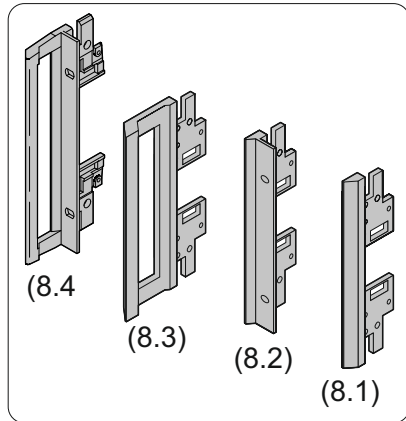

Pos./Item./Rep.	TE/HP/F	mm
16	42	218
16	63	325
16	84	432

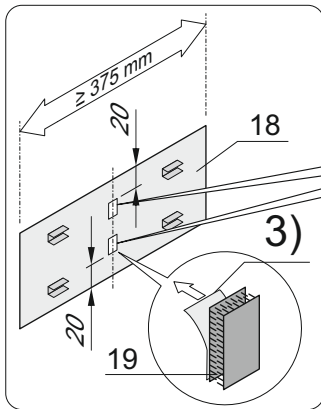

fettfrei / free of grease / sans trace de graisse

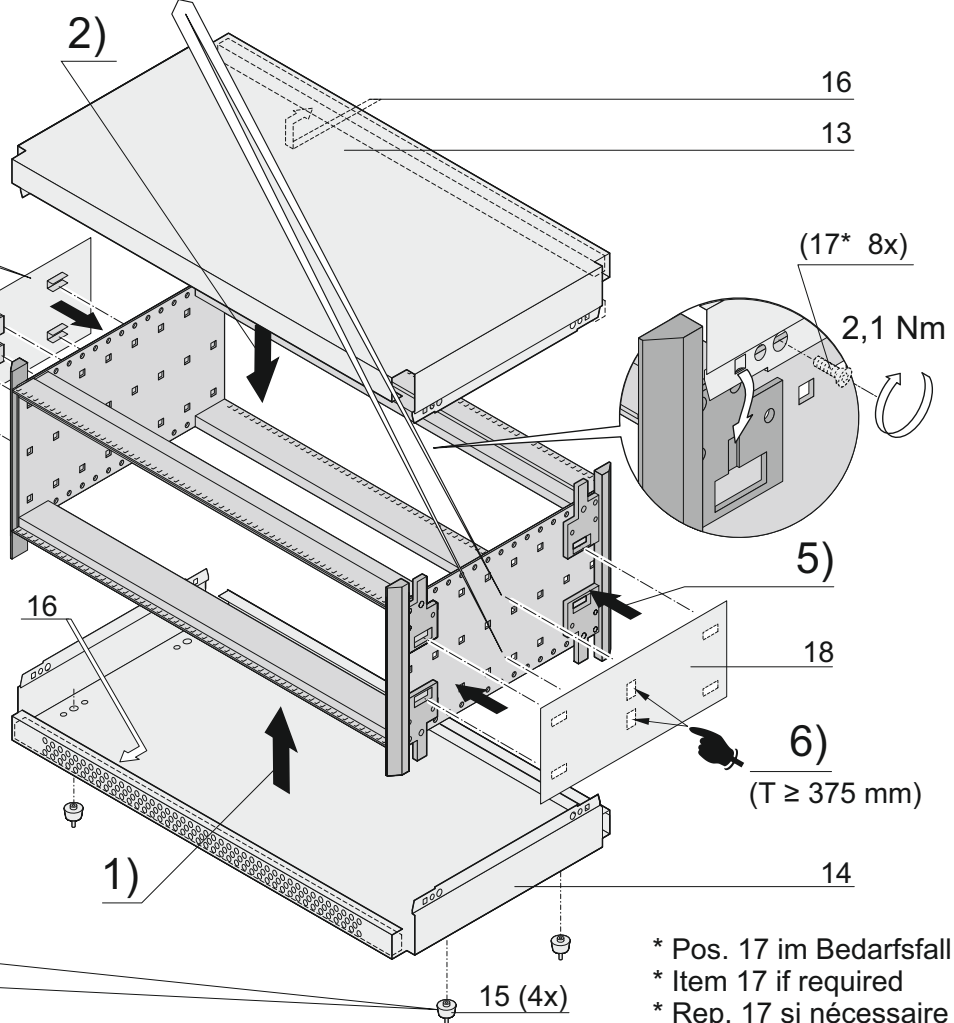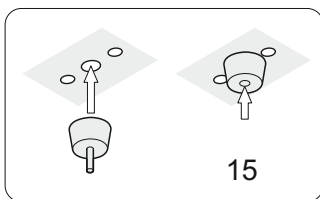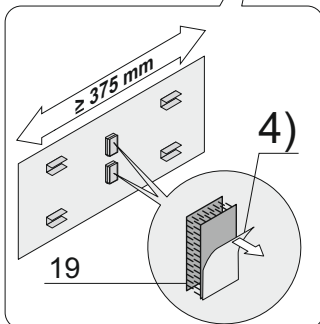

* Pos. 17 im Bedarfsfall
 * Item 17 if required
 * Rep. 17 si nécessaire