




888.747.4533 Toll Free
 805.676.3200 Fax 805.676.3206
 www.SloanLED.com
 5725 Olivas Park Drive, Ventura, CA 93003

INCANDESCENT REPLACEMENT PRODUCTS

MODEL 197

T - 3 ¼ MINIATURE BAYONET CLUSTER LED

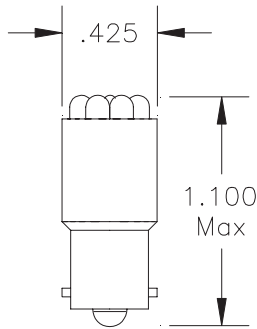


Voltages available from 5 - 48VDC and 5 - 120VAC. Please specify color when ordering. Insert 1 - Red, 2 - Green 3 - Yellow, 4 - Amber, 5 - Ultra Green, 6 - Ultra Blue, 7 - Pure White where "X" appears below. Ultra Bright Blue, Ultra Bright Green and White are configured with a single 5mm LED only. All others are configured with a six T-1 LED cluster.

Voltages	Pos. Ctr.	Neg. Ctr.	Dual Pol.	AC
5vdc/vac	197-PC5X	197-NC5X	197-DP5X	197-AC5X
14vdc/vac	197-PC14X	197-NC14X	197-DP14X	197-AC14X
24vdc/vac	197-PC24X	197-NC24X	197-DP24X	197-AC24X
28vdc/vac	197-PC28X	197-NC28X	197-DP28X	197-AC28X
48vdc/vac	197-PC48X	197-NC48X	197-DP48X	197-AC48X
120vac				197-AC120X

Direct replacement for the following incandescent lamps: 24MB, 28MB, 44, 47, 53, 60RB, 120MB, 194, 256, 313, 356, 363, 756, 757, 1445, 1450, 1495, 1813, 1815, 1816, 1818, 1819, 1820, 1829, 1850, 1855, 1864, 1866, 1891, 1892, 1893.

MODEL 160

T - 4 ½ CANDELABRA LED

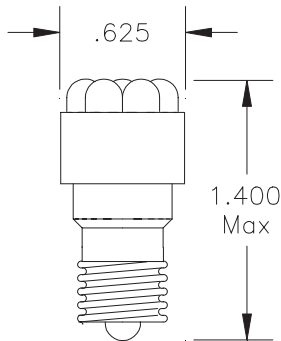

6S6 candelabra screw base LED light. Long life, low power replacement for incandescent lamps. Dual polarity works in both AC and DC applications. Comes with either 4 or 6 LED cluster. Insert 1 - Red, 2 - Green, 3 - Yellow, 4 - Amber, 5 - Ultra Green, 6 - Ultra Blue, 7 - Pure White where "X" appears. When ordering, indicate number of LED's after the model number, voltage and color.

Voltage	Model No.
12	160-12X
24	160-24X
28	160-28X
48	160-48X
60	160-60X
120	160-120X


Direct replacement for 3S6 and 6S6 lamps

How to Order: Model No.-Voltage-Color-Number of LED's

Example: 160-121-6

MODEL 460

STACK LIGHT

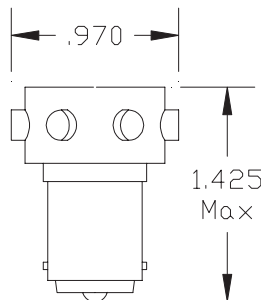

This model is designed to replace incandescent lighting in Stack Lights. Reduce your energy and maintenance cost. Voltages available from 24 to 120 in AC or DC. With 360 degree viewing, these lights are available in all colors. Insert 1 - Red, 2 - Green, 3 - Yellow, 4 - Amber, 5 - Ultra Green, 6 - Ultra Blue, 7 - Pure White where "X" appears below.

Voltages	Model No.
24	460-24X
28	460-28X
60	460-60X
120	460-120X