

3SE2243-0XX40 SAFETY POSITION SWITCH

Technical Data

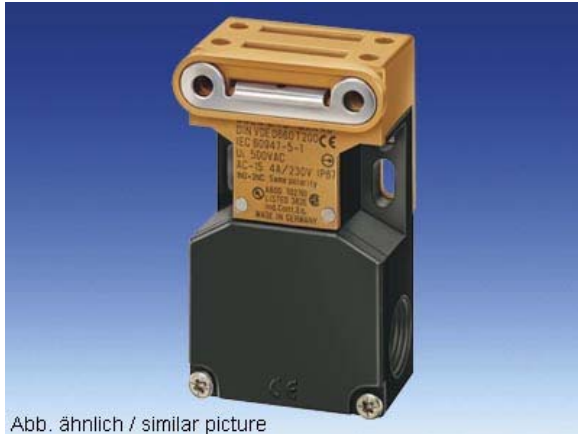


Abb. ähnlich / similar picture

SAFETY POSITION SWITCH WITH SEPARATE ACTUATOR, MOULDED-PLASTIC ENCLOSED, OPERATION FROM THE SIDE AND THE FRONT, 3X (M20X1.5) 1NO+2NC, PULLING FORCE 5N DELIVERED WITHOUT ACTUATOR

General technical details:

Product designation	safety position switch
Active principle	mechanical
Product function / Status display	No

Enclosure:

Design of the housing	wide
Design of the housing / according to standard	No
Material / of the housing	glass fiber reinforced thermoplast
Height of the sensor	90 mm
Length of the sensor	36 mm
Width of the sensor	52 mm

Drive Head:

Contact:

Design of the contact element	slow-action contacts
Number of NC contacts / for auxiliary contact	2
Number of NO contacts / for auxiliary contact	1
Number of change-over switches / for auxiliary contact	0
Design of the switching function	positive opening
Design of the electrical connection	screw-type terminals

Ambient conditions:

Protection class IP	IP65
Ambient temperatureminimum	-
Ambient temperaturemaximum	-

Certificates/approvals:

varification of suitability	CE / UL / CSA / CCC
Acceptability for application / Safety cut-out switch	Yes

