


**90311-004LF - Minitek™ : Crimp-to-Wire
Housing, Double Row, Pol. w/Latch, 4
Position**

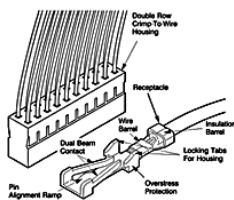

www.fci.com

Specifications

Approvals / Certifications

UL File Number	E66906
CSA File Number	LR46923
Approvals / Certifications	UL and CSA Approved
Mechanical	
Durability (Mating cycles)	100
Electrical	
Withstanding Voltage	650V rms
Current rating	2 amp Continuous
Resistance (Insulation)	1000 M ohms min
General	
Number of contacts (Total)	4
Number of rows	2
Product Type	Crimp-to-Wire Housing
Mating half	Mates with 0.5 (0.02 in.) Square Pin. Mating Pin Length of 3.63 to 4 mm (0.143 to 0.157 in.)
Other Features	
Packaging (Type)	Bag
Center Key Slot	Yes
Physical	
Color (Housing)	Black
Material (Housing)	Thermoplastic
Temperature (Operating - range)	-40°C to +105°C