


**SFW4R-2STE1LF - FPC/FFC : SFW-R series, 4 Pos, Upper Side Contact, Side Entry Surface Mount ZIF Connector, 1 mm (0.039 in.), Lead Free**

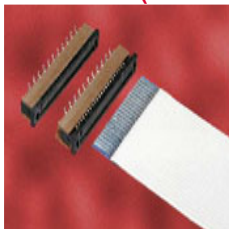

[www.fci.com](http://www.fci.com)

## Specifications

### Approvals / Certifications

Damp Heat per JIS C 0022	Contact Resistance 50 milli ohms max., Insulation Resistance 100 M-ohms min.
Salt Spray per JIS C 0023	Contact Resistance 50 milli ohms max.
Temperature Cycling per JIS C 0025	Contact Resistance 50 milli ohms max.
Vibration per JIS C 0040	No discontinuity > 1 $\mu$ second
<b>Mechanical</b>	
Durability (Mating cycles)	20 Cycles
<b>Electrical</b>	
Withstanding Voltage	500V AC for 1 minute
Current rating	1A AC/DC
Resistance (Contact)	30 milli ohms max.
Resistance (Insulation)	500 M-ohms min.
Voltage rating	100V AC/DC
<b>General</b>	
Cable Insertion	ZIF
Cable Lock	No
Contact location	Upper
Number of contacts	4
Orientation	Right Angle
Product Series	SFW-R
<b>Mounting</b>	
Mounting style (Board)	Surface Mount
<b>Other Features</b>	
Packaging (Type)	Embossed Tape on Reel
<b>Physical</b>	
Cable Type	FPC/FFC
Material (Contact)	Phosphor Bronze, Tin Plated
Material (Housing)	Glass Reinforced PPS, UL94 V-0
Material (Slider)	Glass Reinforced PPS, UL94 V-0
Temperature (Operating - range)	-55°C to +105°C