

American Electrical, Inc.


456 Southlake Blvd,
Richmond, VA 23236

Phone: 804-379-2899 • **Fax:** 804-379-8935

Email: sales@americanelectrical.com • **Website:** www.americanelectrical.com

Item # C15A1P-80VDC, 15 Amp 1 Pole UL 489A Rated DIN Rail Mounted Circuit Breaker

UL 489A
DIN Rail mounted
Compact 13 mm width
One Pole only
Current rating up to 50 A
100% Rating capability
Hydraulic-Magnetic technology
Trip curve U2 standard

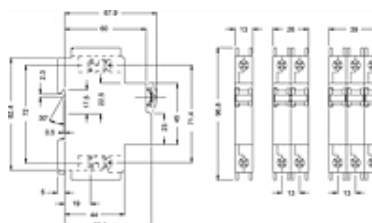






· [SPECIFICATIONS](#) · [CERTIFICATIONS](#)

SPECIFICATIONS

Current	15 A
Width	13 mm
Numbers of Poles	1
Maximum Voltage	80 VDC
Minimum Amp Rating	1 A
Maximum Amp Rating	50 A
Interrupting Cap.	10,000 A
Dielectric Strength	1500 V, 50/60 Hz
Insulation Resistance	100 MΩ

Operating Temp. Range	-40 to +60 °C
Units Per Package	1

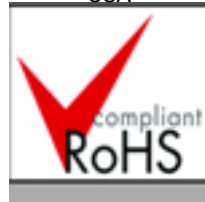CERTIFICATIONS

Certifications	 <p>CE</p>  <p>CSA</p>  <p>RoHS (EU directive 2002/95/EC)</p>  <p>UL Recognized</p>  <p>VDE</p>
----------------	--