


SFW10S-2STME1LF - FPC/FFC : SFW
Straight series, 10 Pos 1 mm (0.039 in.)
Pitch Connector, Top Entry Surface Mount,
ZIF, with Mount Plate

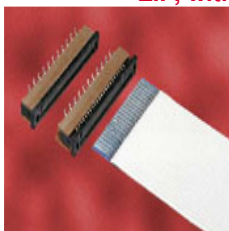

www.fci.com

Specifications

Approvals / Certifications

Damp Heat per JIS C 0022	Contact Resistance 50 milli ohms max., Insulation Resistance 100 M-ohms min.
Salt Spray per JIS C 0023	Contact Resistance 50 milli ohms max.
Temperature Cycling per JIS C 0025	Contact Resistance 50 milli ohms max.
Vibration per JIS C 0040	No discontinuity > 1 μ second
Mechanical	
Durability (Mating cycles)	20 Cycles
Electrical	
Withstanding Voltage	500V AC for 1 minute
Current rating	1A AC/DC
Resistance (Contact)	30 milli ohms max.
Resistance (Insulation)	500 M-ohms min.
Voltage rating	100V AC/DC
General	
Cable Insertion	ZIF
Cable Lock	No
Number of contacts	10
Orientation	Straight
Product Series	SFW-S
Mounting	
Mounting device	Yes
Mounting style (Board)	Surface Mount
Other Features	
Packaging (Type)	Embossed Tape on Reel
Physical	
Cable Type	FPC/FFC
Material (Contact)	Phosphor Bronze, Tin Plated
Material (Housing)	Glass Reinforced PPS, UL94 V-0
Material (Slider)	Glass Reinforced PPS, UL94 V-0
Temperature (Operating - range)	-55°C to +105°C