


MUELLER®

MODEL: BU-P2451

BNC (Female) Flange Mount Connector

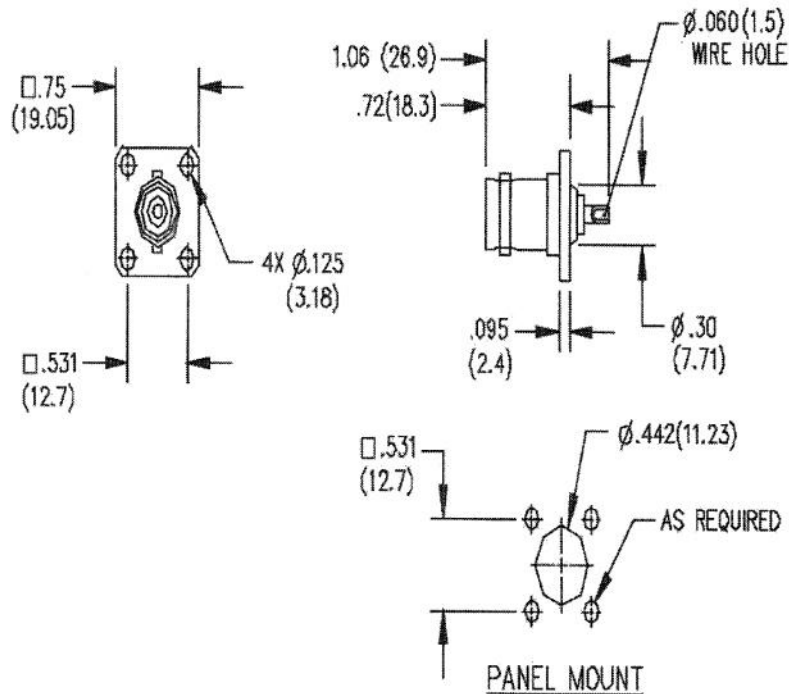

MATERIALS:

Body – Brass, Tarnish resistant plating,

Center Contact – Gold plated copper

Dielectric – PTFE

RATING:

50 Ohms Impedance

30 VAC/60VDC Max shield/earth

500 VRMS Inner conductor/shield

Temperature: -70°C to 170°C