


RS Stock No.517-3888
 RS Stock No.517-3866
 RS Stock No.517-3816
 RS Stock No.517-3822
 RS Stock No.517-3850
 RS Stock No.517-3838
 RS Stock No.517-3894
 RS Stock No.517-3923
 RS Stock No.517-3872
 RS Stock No.517-3939
 RS Stock No.517-3917

Painted Grey high temperature boxes (without seal ,painted Grey)

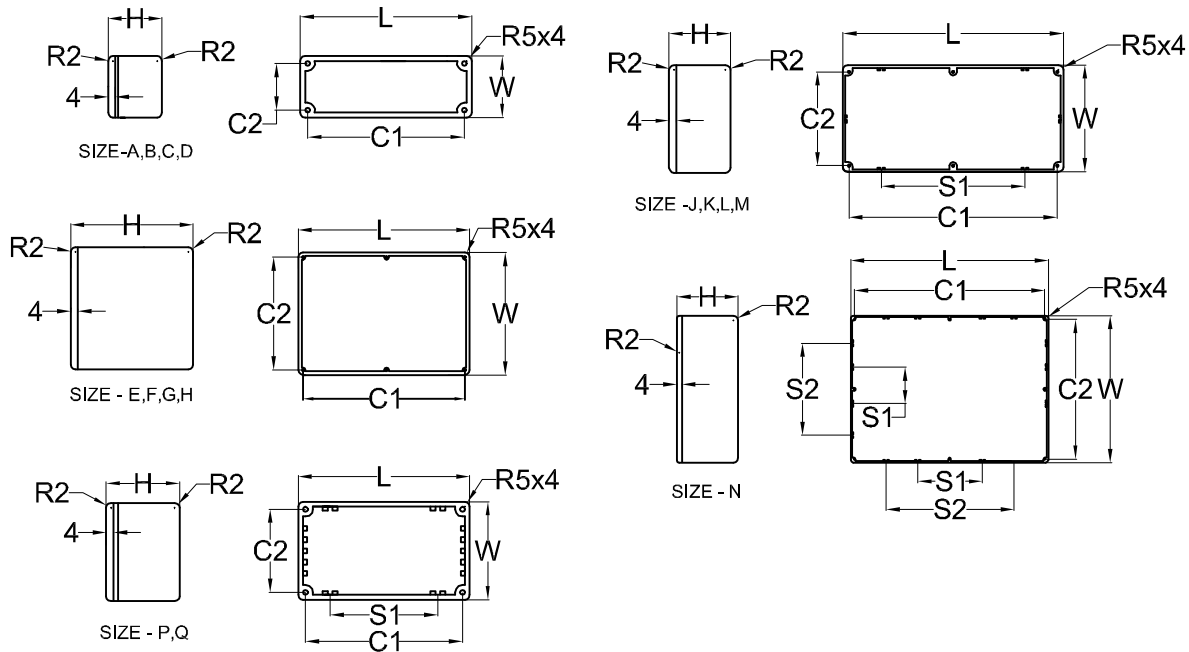

RS Stock NO.	Size NO.	L	W	H	C1	C2	S1	S2	Wall Thickness
5173888	A	89.4	35.3	30.6	79.3	25.3			1.5mm
5173866	B	114.8	63.9	30.6	104.5	54.2			1.5mm
5173816	C	115.0	90.0	55.4	104.4	79.6			2mm
5173822	D	114.7	64.0	55.4	104.6	54.2			2mm
5173850	E	172.3	121.2	55.3	160.4	109.3			2mm
5173838	G	222.4	146.2	56.2	211.7	135.4			2mm
5173894	H	222.5	146.3	106.8	211.7	135.4			2mm
5173923	J	275.3	175.3	65.8	264.1	164.0	132.2		2mm
5173872	K	139.4	101.8	77.0	128.7	90.7	64.8		2mm
5173939	L	166.1	127.6	76.6	154.0	116.1	77.1		2mm
5173917	N	250.5	250.5	100.8	238.0	238.0	79.9	160.0	2.5mm

1. Material of the base and lid :Aluminium alloy ADC12
2. Material of the screws : Stainless M3.5x9mm Supadrive countersunk head
3. Finish:Painting
 - 3-1. Thickness:60~80 Micron (1.5um~2.0um)
 - 3-2. Colour:Grey RAL 7023
4. Taper 1.5° Per side lid to base

