



QUICK DISCONNECTS



TE CONNECTIVITY (TE)

.250 SRS FASTIN FASTON RECEPTA

[FASTIN-FASTON](#) | [FASTON Terminals and Housings](#)

154661-2

TE Internal Number: 154661-2

Always EU RoHS/ELV Compliant

Mating Tab Width **6.35 mm [.25 in]**

Mating Tab Thickness **.81 mm [.032 in]**

Wire Insulation Diameter **2.16 – 3.18 mm [.085 – .125 in]**

Wire Size (AWG) **22 – 18**

Wire Size (mm²) **.3 – .9**

Active

3D PDF

CAD Files

3D PDF

PDF
3D

Customer View Model

2D_DXF.ZIP
English

Customer View Model

3D_IGS.ZIP
English

Customer View Model

3D_STP.ZIP
English

Catalog Pages/Data Sheets

1654742_HOUSEHOLD_APPLIANCES_RAST5

PDF
English

Please review product documents or [contact us](#) for the latest agency approval information.

Product Type Features

 
 
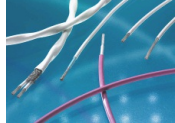

Wire Stop	No
Disconnect Type	Quick Disconnect
Insertion Force	Normal
FASTON	Yes
Wire/Cable Type	Regular Wire
Insulated Wire Support	Yes
Applies To	Wire/Cable

Configuration Features

Terminal Angle	Straight
----------------	-----------------

	Connection Capacity	Single
Body Features	Plating Material	Brass, Tin
Contact Features	Terminal Orientation	Straight
Termination Features	Crimp Type	F-Crimp
Mechanical Attachment	Mating Retention Type	Locking Lance
Dimensions	Mating Tab Width	6.35 mm [.25 in]
	Mating Tab Thickness	.81 mm [.032 in]
	Wire Insulation Diameter	2.16 – 3.18 mm [.085 – .125 in]
	Wire Size (AWG)	22 – 18
	Wire Size (mm ²)	.3 – .9
	Material Thickness	.3 mm [.012 in]
	Overall Length	20.32 mm [.8 in]
Operation/Application	For Housing Type	Multiple
Industry Standards	UL Rating	Recognized
	CSA Certified	Yes
Packaging Features	Packaging Method	Box
	Packaging Quantity	500
Other	Comment	Without Dimple
Product Compliance	Statement of Compliance PDF VIEW ALL PRODUCT COMPLIANCE	

CUSTOMERS ALSO BOUGHT

<p>THROUGH-HOLE RESISTORS</p> 	<p>CRIMP RINGS & SPADES</p> 	<p>TWISTED PAIR CABLE</p> 	<p>SURFACE MOUNT RESISTORS</p> 
---	---	---	--

SQB20 22R 5% (WIRE)
SQBW2022RJ

B-106-1401CS100
CC2620-000

55A0121-22-2/6
55A0121-22-2/6

CPF 0402 5K9 0.1% 25PPM
1K RL
CPF0402B5K9E1

 Save to List

 Find Similar Products

 Save to List

 Find Similar Products

 Save to List

 Find Similar Products

 Save to List

 Find Similar Products