




925712-1 Product Details

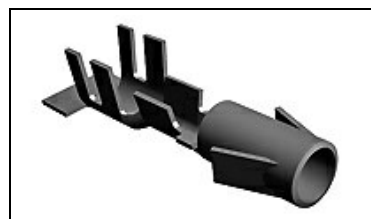

925712-1

TE Internal Number: 925712-1

Active

.240, .295" Centerline, 250 v, 28 A max. (.140" MATE-N-LOK)

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Contact
- Contact Type = Socket
- Applies To Wire/Cable
- Wire/Cable Type = Discrete Wire
- Packaging Method = Strip

[View all Features](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [View Housings \(13\)](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

[Add to My Part List](#) |
 [Request Sample](#) |
 [Find Similar Products](#) |
 [Buy Product](#)

Documentation & Additional Information

Documents are temporarily unavailable. We are working hard to correct the problem. Please try again later.

Additional Information:

- [Product Line Information](#)

Related Products:

- [Tooling](#)
- [Housings \(13\)](#)

Product Features (Please use the Product Drawing for all design activity)

Product Type Features:

- [Product Type](#) = Contact
- [Wire/Cable Type](#) = Discrete Wire
- [Wire Insulation Diameter \(mm \[in\]\)](#) = 2.50 - 4.50 [0.098 - 0.177]
- [Connector Line](#) = .140 MATE-N-LOK

Electrical Characteristics:

- [Current Rating \(A\)](#) = 28
- [Voltage \(VAC\)](#) = 250

Body Features:

- [Wire Range \(mm \[AWG\]\)](#) = 2.00-6.00² [14-10]
- [Spare Tube](#) = 725939-0
- [Stock Thickness \(mm \[in\]\)](#) = 0.35 [0.014]

Contact Features:

- [Contact Type](#) = Socket
- [Contact Base Material](#) = Brass
- [Contact Diameter \(mm \[in\]\)](#) = 3.56 [0.140]
- [Solder Tail Contact Plating](#) = Pre-Tin

Industry Standards:

- [RoHS/ELV Compliance](#) = RoHS compliant, ELV compliant
- [Lead Free Solder Processes](#) = Not relevant for lead free process
- [RoHS/ELV Compliance History](#) = Always was RoHS compliant

Conditions for Usage:

- [Applies To](#) = Wire/Cable

Packaging Features:

- [Packaging Method](#) = Strip

Other:

- [Brand](#) = AMP

Corporate Information

- [About TE](#)
- [Investors](#)
- [News Room](#)
- [Supplier Portal](#)
- [Careers](#)
- [Terms & Conditions](#)
- [Privacy Policy](#)
- [AODA Accessibility Policy](#)
- [AODA Multi-Year Accessibility Plan](#)

Quick Links

- [Distributor Inventory](#)
- [Product Cross Reference](#)
- [Documents & Drawings](#)
- [Product Compliance Support Center](#)
- [Site Map](#)

Customer Support

- [Email or Chat With Us](#)
- [Find a Phone Number](#)
- [Knowledge Base](#)
- [Manage Your Account](#)

Keep Me Informed



