


925712-2 Product Details

[Share](#) [Print](#) [Email](#)

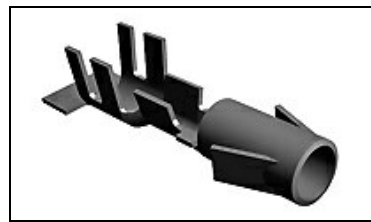

925712-2

.240, .295" Centerline, 250 v, 28 A max. (.140" MATE-N-LOK)

Always EU RoHS/ELV Compliant (Statement of Compliance)

Product Highlights:

- Contact
- Contact Type = Socket
- Applies To Wire/Cable
- Wire/Cable Type = Discrete Wire
- Packaging Method = Strip

[View all Features](#)

TE Internal Number: 925712-2

Active

[Add to My Part List](#) [Request Sample](#) [Find Similar Products](#) [Buy Product](#)

Quick Links

- ▶ [Pricing & Availability](#)
- ▶ [Search for Tooling](#)
- ▶ [View Housings \(13\)](#)
- ▶ [Product Feature Selector](#)
- ▶ [Contact Us About This Product](#)

Documentation & Additional Information	
<p>Documents are temporarily unavailable. We are working hard to correct the problem. Please try again later.</p>	<p>Additional Information:</p> <ul style="list-style-type: none"> • Product Line Information <p>Related Products:</p> <ul style="list-style-type: none"> • Tooling • Housings (13)

Product Features (Please use the Product Drawing for all design activity)	
<p>Product Type Features:</p> <ul style="list-style-type: none"> • Product Type = Contact • Wire/Cable Type = Discrete Wire • Wire Insulation Diameter (mm [in]) = 2.50 - 4.50 [0.098 - 0.177] • Connector Line = .140 MATE-N-LOK <p>Electrical Characteristics:</p> <ul style="list-style-type: none"> • Current Rating (A) = 28 • Voltage (VAC) = 250 <p>Body Features:</p> <ul style="list-style-type: none"> • Wire Range (mm [AWG]) = 2.00-6.00² [14-10] • Spare Tube = 725939-0 • Stock Thickness (mm [in]) = 0.35 [0.014] <p>Contact Features:</p> <ul style="list-style-type: none"> • Contact Type = Socket • Contact Base Material = Phosphor Bronze • Contact Diameter (mm [in]) = 3.56 [0.140] • Solder Tail Contact Plating = Pre-Tin 	<p>Industry Standards:</p> <ul style="list-style-type: none"> • RoHS/ELV Compliance = RoHS compliant, ELV compliant • Lead Free Solder Processes = Not relevant for lead free process • RoHS/ELV Compliance History = Always was RoHS compliant <p>Conditions for Usage:</p> <ul style="list-style-type: none"> • Applies To = Wire/Cable <p>Packaging Features:</p> <ul style="list-style-type: none"> • Packaging Method = Strip • Packaging Quantity = 7,500 <p>Other:</p> <ul style="list-style-type: none"> • Brand = AMP

<p>Corporate Information</p> <ul style="list-style-type: none"> About TE Investors News Room Supplier Portal Careers Terms & Conditions Privacy Policy AODA Accessibility Policy AODA Multi-Year Accessibility Plan 	<p>Quick Links</p> <ul style="list-style-type: none"> Distributor Inventory Product Cross Reference Documents & Drawings Product Compliance Support Center Site Map 	<p>Customer Support</p> <ul style="list-style-type: none"> Email or Chat With Us Find a Phone Number Knowledge Base Manage Your Account 	<p>Keep Me Informed</p>
---	---	--	--------------------------------

